


PATLITE®

DIGEST CATALOG

2021



History of PATLITE

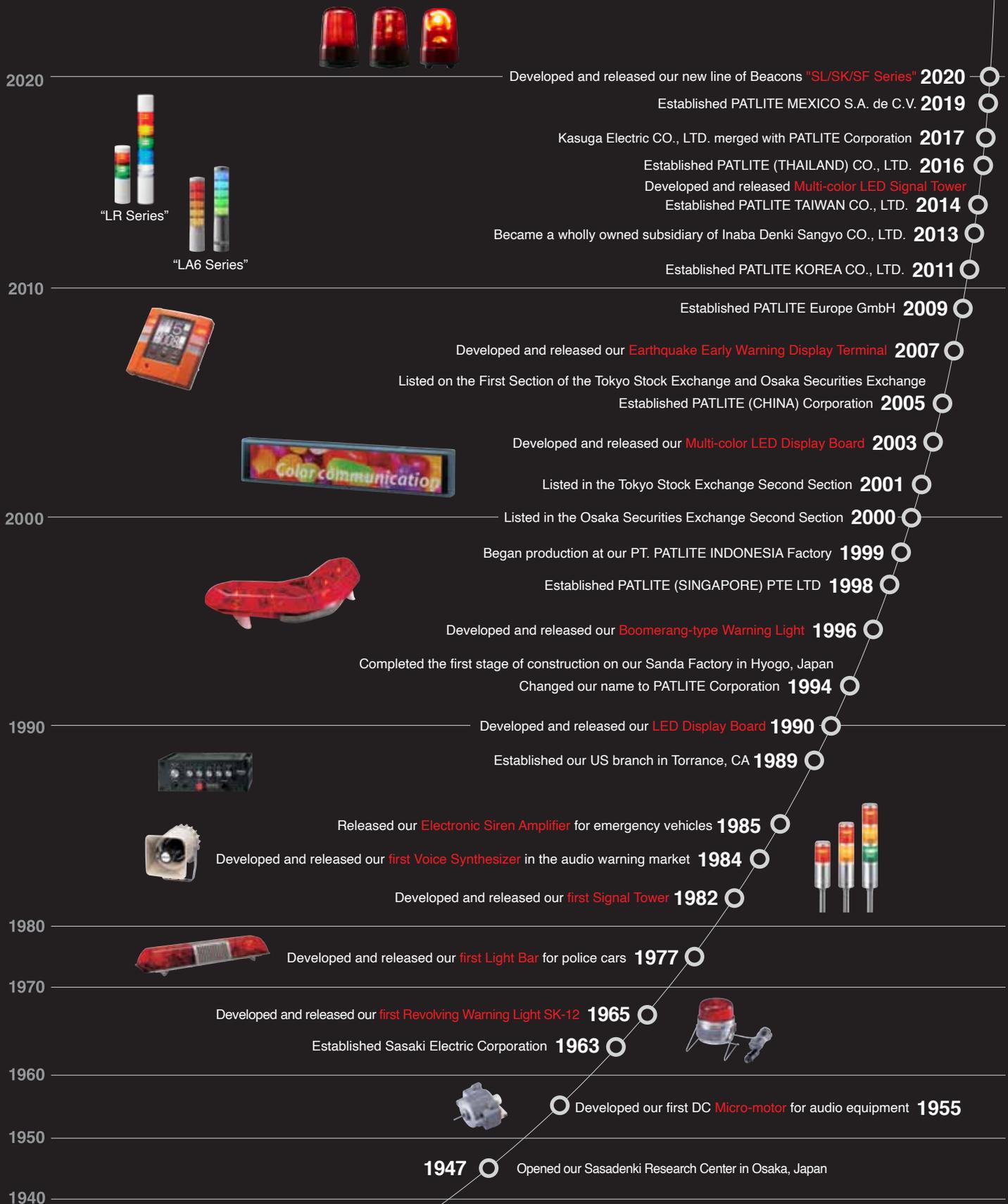

IO-Link Signal Beacons **NE-IL**

- Φ56mm
- IP65
- NEMA 4X/13
- 88 dB at 1 m
- Touch Sensor
- M12
- 1 Analog Input | 1 Digital Input

7 colors in one unit



IO-Link Signal Tower **LR6-IL**

- Φ60mm
- IP65
- NEMA 4X/13
- 84 dB at 1 m
- M12
- WD Compatible



Body unit (Direct mount) Body unit (Direct/NPT mount) Pre-assembled

Multi-color 7 colors in one unit

- Φ56mm
- IP67
- IP65 (Alarm)
- NEMA 4X/13
- 88 dB at 1 m
- Touch Sensor
- Cable 2m



Mono-color

- Φ56mm
- IP65
- Screwless Terminal Block
- NEMA 4X/13



Wireless Data Acquisition System **WD Series and LR Series**

The WD Series is an add-on solution for select PATLITE Signal Towers enabling wireless data acquisition and real-time monitoring.



WD Series



WD PRO Series

(More data points than WD series)

WD PRO Series availability varies by country. Please consult PATLITE for more product details and availability information.



Network Monitoring Signal Tower

NH-3FV2



LAN	RSH	SNMP v1-2c	MP3
88 dB at 1 m	10 Sounds	60 Messages	4 Inputs
1 Output	HTTP	NHP $\Phi 40\text{mm}$	NHL $\Phi 60\text{mm}$



NH-3FB2



LAN	RSH	SNMP v1-2c
80 dB at 1 m	4 Sounds	HTTP
NHP $\Phi 40\text{mm}$	NHL $\Phi 60\text{mm}$	



Network Signal Tower

LA6-POE

LAN	Modbus/TCP	IP54
85 dB at 1 m	11 Sounds	HTTP
PoE	$\Phi 60\text{mm}$	21 Colors LED

PoE : Power over Ethernet



Direct mount type

Desktop type

Signal Beacons

NEW BEACON LINE



LED Life 100,000 hours *1

IP66 *2

IP65 *3

NEMA 4X/13

88 dB at 1 m *4

SL

SL08 $\Phi 80\text{mm}$	SL10 $\Phi 100\text{mm}$	SL15 $\Phi 150\text{mm}$
-------------------------	--------------------------	--------------------------

Select from 3 light patterns

Continuous	Blinking	Triple Flash
------------	----------	--------------



SF

SF08 $\Phi 80\text{mm}$	SF10 $\Phi 100\text{mm}$
-------------------------	--------------------------

Select from 22 light patterns

Rotating	Flash	Pulse
• 60rpm	• Single	Dimmed
• 120rpm	• Double	Half-side
• 180rpm	• Triple	



SK

SKS $\Phi 80\text{mm}$	SKH $\Phi 100\text{mm}$	SKP $\Phi 150\text{mm}$
------------------------	-------------------------	-------------------------

Rotating 120rpm



USB Signal Tower


LR6-USB



Black

Off-white

USB Connection

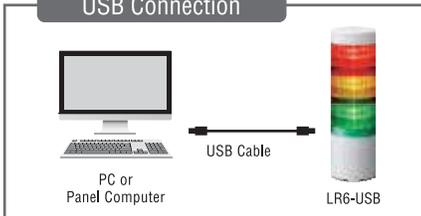

PHE-3FB3



Interface Converter

NBM-D88N



PHC-D08N



Global AC Adaptor

(For NH Series, PHE, NBM, PHC)

ADP-001

Compatible Regions:
Japan, USA, Canada, Europe, China,
Taiwan, Korea, Indonesia, Thailand,
Philippines, Vietnam



RLR



Φ162mm

LED IP66

105rpm

(RLR-M2 not CE Compliant)



LPT

LED Life
100,000
hours

IP68

NEMA TYPE
4X,13



86×28mm
(LPT-1M1)

114.4×43.4mm
(LPT-2M1)

Select from 4 light patterns

Triple Flash Extreme Waring Flash

Continuous On Blinking



LPT-1M1



LPT-2M1

LFH



Φ100mm

LED

IP66 Triple Flash

(LFH-48 not CE Compliant)



PFH-BT



Φ100mm

LED

IP55

Single Flash

Double Flash

Battery-operated



LED Signal Towers

Slim Towers



MP-B

1 Sound 80 dB at 1 m



ME-A

Φ25mm

LED

IP42

NPN Open Collector



MP

Φ30mm

LED

IP65

M-12 Connector

Open Collector



LR4

Φ40mm

Modular Type

LED

85 dB at 1 m

4 Sounds

IP65

NEMA 4X/13

Open Collector



Off-white / Silver

LR5

Φ50mm

Modular Type

LED

85 dB at 1 m

4 Sounds

IP65

NEMA 4X/13

Open Collector



Off-white / Silver / Black

LR6

Φ60mm

Modular Type

LED

88 dB at 1 m

4 Sounds

IP65

NEMA 4X/13

Open Collector



Off-white / Silver

LR7

Φ70mm

Modular Type

LED

90 dB at 1 m

4 Sounds

IP65

NEMA 4X/13

Open Collector



Off-white / Silver / Black

LR Series Modular Components



Body Units



Buzzer Units



LED Units

LED Work Lights

CWA



IP65

DAYLIGHT COLOR (C-D)
6500K




CWF



IP20

DAYLIGHT COLOR (C-D)
5700K

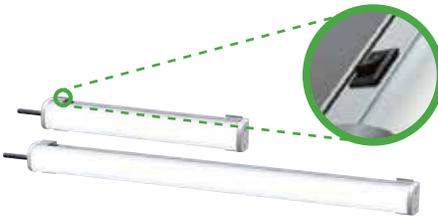

(24V DC / 100-240V AC Available*)
*100-240V AC not CE Compliant

CLN-A



IP66G

IP67G

IP69K

DAYLIGHT COLOR (C-D)
6500K



CLK-SA/SG



IP66G

IP67G

IP69K

DAYLIGHT COLOR (C-D)
6500K

NATURAL WHITE COLOR (F-M)
5000K



CWK



IP66G

IP67G

DAYLIGHT COLOR (C-D)
6500K



CLA-A



IP66

IP67

IP69K

DAYLIGHT COLOR (C-D)
6500K

Amber LED



CLK



IP66G

IP67G

IP69K

DAYLIGHT COLOR (C-D)
6500K

NATURAL WHITE COLOR (F-M)
5000K



INNOVATIVE MODEL

LA6

- Φ60mm
- IP54 (Alarm)
- 21 Colors LED
- Open Collector
- 85 dB at 1 m
- Single Display
- 11 Sounds
- Time-trigger
- IP65
- Pulse-trigger



Off-white / Silver



UNIQUE DESIGN MODELS

Smooth & Stylish

LS7

- Φ70mm
- LED
- 85 dB at 1 m
- 2 Sounds
- IP65
- IP54 (Alarm)
- Open Collector



Off-white / Silver / Dark Gray



Wall Mount

WE

- W90mm
D37.5mm
- LED
- 90 dB at 1 m
- 2 Sounds
- IP65
- Open Collector



Ivory / Silver



Wall Mount

WME-D

- W70mm
D80mm
- LED
- 93 dB at 1 m
- 2 Sounds
- IP54
- Open Collector



Off-white



Audible Products

BSV/BSV-L



- MP3
- 87 dB at 1 m
- 63 second Playback
- 520 second Playback
- IP54
- PNP Open Collector
- NPN Open Collector
- BSV
- BSV-L



Off-white

Silver

Dark Gray

BK/BKV



- MP3
- 95 dB at 1 m
- 63 second Playback
- IP54
- NPN Open Collector
- BKV



Dark Gray

Ivory

EHS/EHV



(12/24V DC: CE Compliant)

- MP3
- 110 dB at 1 m
- IP65
- NPN Open Collector
- PNP Open Collector
- 32 Sounds
- 63 Sounds
- 220 second Playback
- EHS
- EHV
- EHV



LKEH



- MP3
- LED
- 105 dB at 1 m
- IP53
- NPN Open Collector
- 32 Sounds
- 63 second Playback
- LKEH-FV



※ UL type : Special Order.


Options

SD Card (2 GB)
SDV-2GP*



*not CE Compliant

PATLITE Global Network

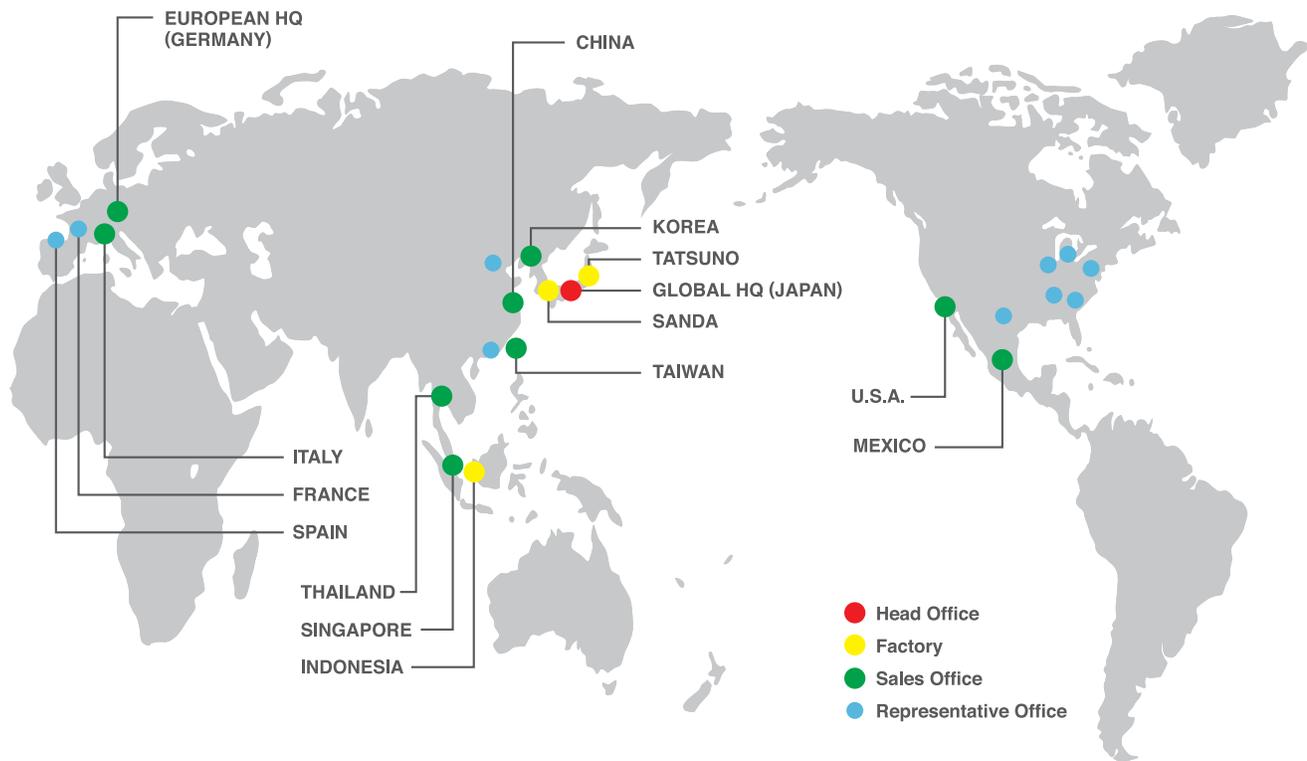

PATLITE (U.S.A.) Corporation

20130 S. Western Ave. Torrance, CA 90501, U.S.A.
 TEL.+1-310-328-3222 FAX.+1-310-328-2676 E-mail: sales@patlite.com

PATLITE Corporation

4-1-3, Kyutaromachi, Chuo-ku, Osaka 541-0056 Japan
 International Sales Division
 TEL.+81-6-7711-8953 FAX.+81-6-7711-8961 E-mail: overseas@patlite.co.jp

PATLITE (SINGAPORE) PTE LTD

No.2 Leng Kee Road, #05-01 Thye Hong Centre, Singapore 159086
 TEL.+65-6226-1111 FAX.+65-6324-1411 E-mail: sales@patlite.com.sg

PATLITE (CHINA) Corporation

Room 1102-1103, No.55, Lane 777, Guangzhong Road (West), Jing an District, Shanghai, China
 TEL.+86-21-6630-8969 FAX.+86-21-6630-8938 E-mail: sales@patlite.cn

PATLITE Europe GmbH

Am Soeldnermoos 8, D-85399 Hallbergmoos, Germany
 TEL.+49 -811-9981-9770-0 FAX.+49-811-9981-9770-90 E-mail: info@patlite.eu
 WEEE Reg. Nr. 67267160

PATLITE KOREA CO., LTD.

A-2603, Daesung D-POLIS, 606, Seobusaet-gil, Geumcheon-gu, Seoul, 08504, Korea
 TEL.+82-2-523-6636 FAX.+82-2-861-9919 E-mail: sales@patlite.co.kr

PATLITE TAIWAN CO., LTD.

2F-1, No.215, Sec. 2, Chengde Rd., Datong Dist., Taipei City 10364, Taiwan (R.O.C.)
 TEL.+886-2-2552-9611 FAX.+886-2-2552-9811 E-mail: info@patlite.tw

PATLITE (THAILAND) CO., LTD.

Olympia Thai Tower, 15th Floor 444 Ratchadapisek Road Samsenok, Huay Kwang Bangkok 10310, Thailand
 TEL.+66-2-541-5431 FAX.+66-2-541-5429 E-mail: sales_150716@patlite.co.th

PATLITE MEXICO S.A. de C.V.

Plaza de La Paz No. 102, int. 712 Guanajuato Puerto Interior, Silao, Gto, C.P.36275, Mexico
 TEL.+52-472-748-9124 E-mail: ventas@patlite.com.mx

www.patlite.com

- PATLITE, the PATLITE logo are either registered trademarks or trademarks of PATLITE Corporation in JAPAN and/or other countries.
- MPEG Layer-3 audio coding technology licensed from Fraunhofer IIS and Thomson Licensing.
- The names of other companies and products are trademarks or registered trademarks of their respective companies.