



# LED Designer Deco

## 1S14/VIN/827/CL/G/E26/ND 1CT

Philips LED Designer Deco lamps allow you to maintain a warm, classic light or a modern, chic effect while providing longer life and energy savings


### Product data

General information	
Base	E26 [ Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	20000
Light technical	
Color Code	827 [ CCT of 2700K]
Initial lumen (Nom)	60 lm
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	2700 K
Luminous Efficacy (rated) (Nom)	60.00 lm/W
Color Consistency	<4
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and electrical	
Input Frequency	50 to 60 Hz
Power (Rated) (Nom)	1 W
Lamp Current (Nom)	12 mA
Wattage Equivalent	10 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.5
Voltage (Nom)	110-130 V

Temperature	
T-Case Maximum (Nom)	78.8 °F
Controls and dimming	
Dimmable	No
Mechanical and housing	
Bulb Finish	Clear
Bulb Material	Glass
Bulb Shape	S14 [ S14]
Approval and application	
Energy Certifications	No
Product data	
Order product name	1S14/VIN/827/CL/G/E26/ND 1CT
EAN/UPC - Product	046677575205
Order code	575209
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929003082704
Net Weight (Piece)	0.035 lb

# LED Designer Deco


## Dimensional drawing

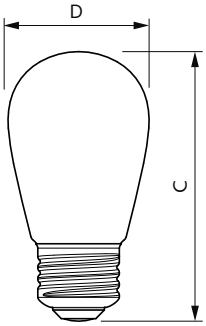


1S14/VIN/827/CL/G/E26/ND 1CT

Product	D	C
1S14/VIN/827/CL/G/E26/ND 1CT	1-13/16 in	3-7/16 in


## Photometric data

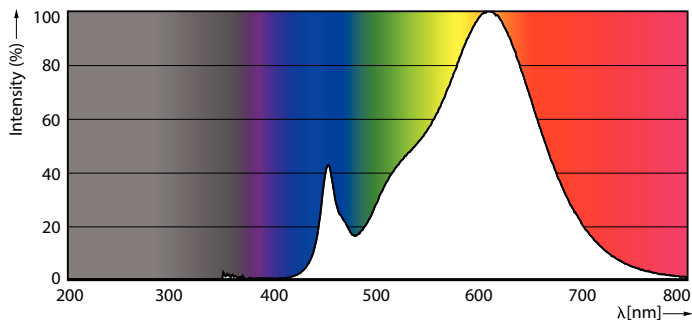

LEDbulb NAM 1W S14 E26 827 CL-POC

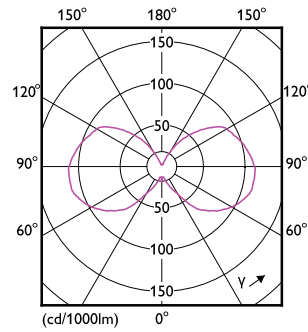

LEDbulb NAM S14 1W E26 827 CL-LDD

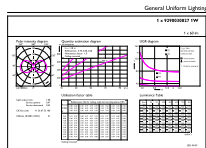


Page 17

LEDbulb NAM 1W S14 E26 827 CL-GUL

# LED Designer Deco

## Lifetime

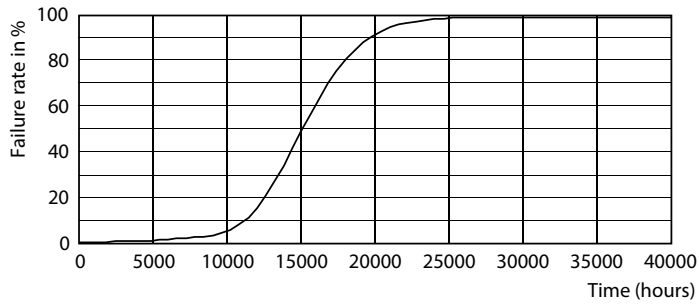

Life Expectancy Diagram

Lumen Maintenance Diagram

