

LED Designer Deco

5ST19/VIN/820/E26/CL/GL/DIM 4/1FBH T20


Philips LED Designer Deco lamps allow you to maintain a warm, classic light or a modern, chic effect while providing longer life and energy savings

Product data

General information	
Base	E26 [Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	20000X
Light technical	
Color Code	820 [CCT of 2000K]
Initial lumen (Nom)	350 lm
Color Designation	Flame
Correlated Color Temperature (Nom)	2000 K
Luminous Efficacy (rated) (Nom)	70.00 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	5 W
Lamp Current (Nom)	50 mA
Wattage Equivalent	40 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.7

Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	126 °F
Controls and dimming	
Dimmable	Yes
Mechanical and housing	
Bulb Finish	Amber
Bulb Material	Glass
Bulb Shape	ST19
Approval and application	
Energy Consumption kWh/1000 h	- kWh
Energy Certifications	No
Product data	
Order product name	5ST19/VIN/820/E26/CL/GL/DIM 4/1FBH T20
EAN/UPC - Product	046677556808
Order code	556803
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	4
Material Nr. (12NC)	929001951033
Net Weight (Piece)	0.066 lb


Dimensional drawing

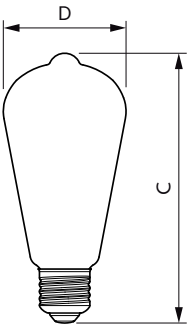


5ST19/VIN/820/E26/CL/GL/DIM 4/1FBH T20

Product	D	C
5ST19/VIN/820/E26/CL/GL/DIM 4/1FBH T20	2-9/16 in	5-7/16 in


Photometric data

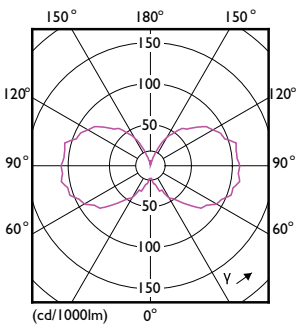

LEDbulb ST19 5W E26 820 Amber

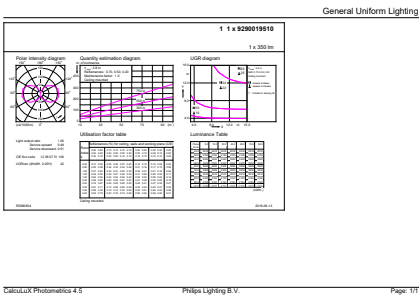

LEDbulb 5W ST19 E26 820 Amber

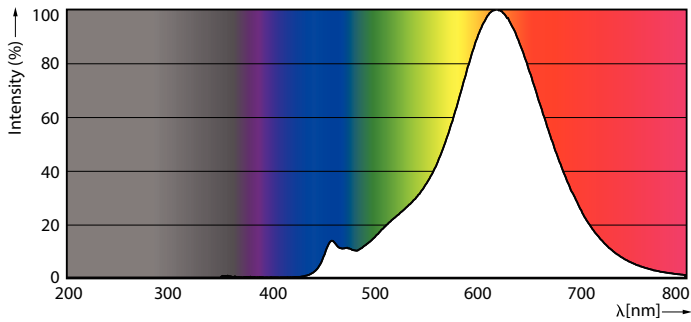

LEDbulb 5W ST19 E26 820 Amber

Lifetime



Life Expectancy Diagram



Lumen Maintenance Diagram

