

LED Designer Deco

8ST19/PER/927-922/CL/G/E26/WGX PF T20


Philips LED Designer Deco lamps allow you to maintain a warm, classic light or a modern, chic effect while providing longer life and energy savings

Product data

General information	
Base	E26 [Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	20000
Light technical	
Color Code	927-922 [CCT of 2700K-2200K]
Beam Angle (Nom)	280 °
Initial lumen (Nom)	800 lm
Color Designation	Warm Glow(WG)
Correlated Color Temperature (Nom)	2700 2200 K
Luminous Efficacy (rated) (Nom)	100.00 lm/W
Color Consistency	<4
Color Rendering Index (Nom)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	8 W
Lamp Current (Nom)	85 mA
Wattage Equivalent	40 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.7

Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	140 °F
Controls and dimming	
Dimmable	Yes
Mechanical and housing	
Bulb Finish	Clear
Bulb Material	Glass
Bulb Shape	ST19
Approval and application	
Energy Consumption kWh/1000 h	- kWh
Energy Certifications	No
Product data	
Order product name	8ST19/PER/927-922/CL/G/E26/WGX PF T20
EAN/UPC - Product	046677556532
Order code	556530
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	4
Material Nr. (12NC)	929002296003
Net Weight (Piece)	0.066 lb


Dimensional drawing

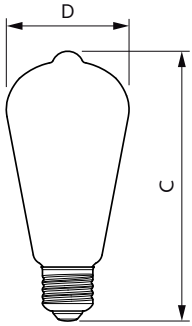


8ST19/PER/927-922/CL/G/E26/WGX PF T20

Product	D	C
8ST19/PER/927-922/CL/G/E26/WGX PF T20	2-9/16 in	5-5/8 in


Photometric data

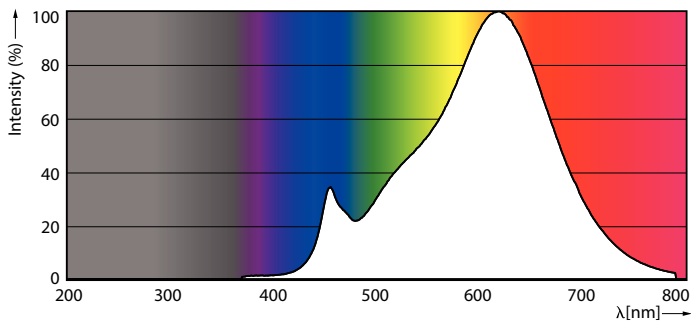

LEDbulb 8W ST19 E26 927 922 CL

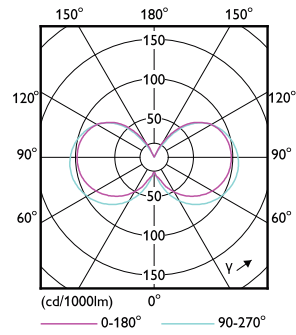


LEDbulb ST19 8,8W E26 950 CL

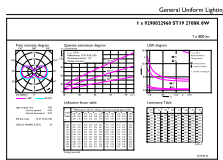

LEDbulb 8W ST19 E26 927 922 CL

LED Designer Deco

Lifetime

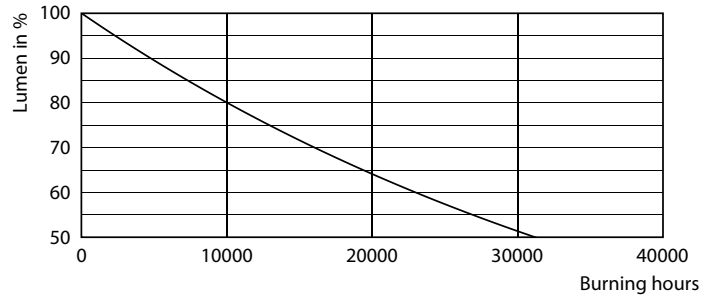

Life Expectancy Diagram

Lumen Maintenance Diagram

