



# A-Shape LED

## 12.2A19/PER/927-22/P/E26/WG 6/1FB T20

Philips A-shape LED lamps are the LED alternative to standard incandescents. It provides beautiful light and dependable performance you expect from LED at an affordable price.


### Product data

General information		Power Factor (Nom)	
Base	E26 [ Single Contact Medium Screw]		0.7
EU RoHS compliant	Yes	Voltage (Nom)	120 V
Nominal Lifetime (Nom)	15000 h	<b>Temperature</b>	
Switching Cycle	50000	T-Case Maximum (Nom)	185 °F
<b>Light technical</b>		<b>Controls and dimming</b>	
Color Code	922-927 [ CCT of 2200K-2700K]	Dimmable	Yes
Beam Angle (Nom)	250 °	<b>Mechanical and housing</b>	
Initial lumen (Nom)	1100 lm	Bulb Finish	Frosted
Color Designation	Warm Glow(WG)	Bulb Material	Plastic
Correlated Color Temperature (Nom)	2200 2700 K	Bulb Shape	A19 (A19)
Luminous Efficacy (rated) (Nom)	90.00 lm/W	<b>Approval and application</b>	
Color Consistency	<4	Energy Consumption kWh/1000 h	- kWh
Color Rendering Index (Nom)	90	Energy Certifications	Energy Star
LLMF At End Of Nominal Lifetime (Nom)	70 %	<b>Product data</b>	
<b>Operating and electrical</b>		Order product name	12.2A19/PER/927-22/P/E26/WG 6/1FB T20
Input Frequency	60 Hz	EAN/UPC - Product	046677561000
Power (Rated) (Nom)	12.2 W	Order code	561000
Lamp Current (Nom)	100 mA	Numerator - Quantity Per Pack	1
Wattage Equivalent	75 W	Numerator - Packs per outer box	6
Starting Time (Nom)	0.5 s		
Warm Up Time to 60% Light (Nom)	0.5 s		

# A-Shape LED

Material Nr. (12NC)	929002285404
Net Weight (Piece)	0.132 lb


## Dimensional drawing

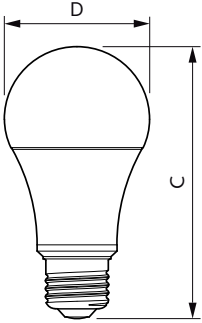


12.2A19/PER/927-22/P/E26/WG 6/1FB T20

Product	D	C
12.2A19/PER/927-22/P/E26/WG 6/1FB T20	2-3/8 in	4-7/16 in


## Photometric data

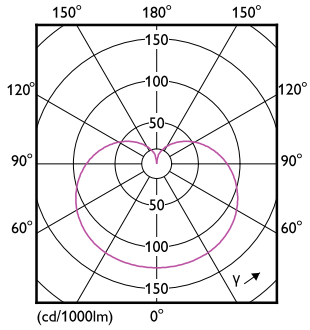

LEDbulb A19 12,2W E26 1100lm 950 FR

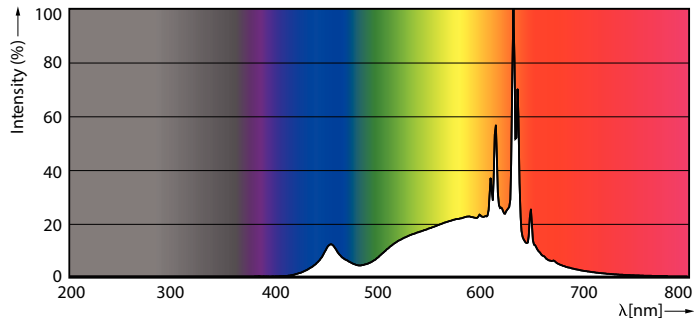

LEDbulb 12,2W A19 E26 922 927 FR

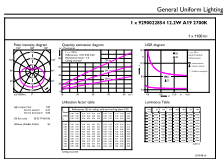

LEDbulb 12,2W A19 E26 922 927 FR

# A-Shape LED

## Lifetime



Life Expectancy Diagram

Lumen Maintenance Diagram

