



A-Shape LED

12.2A19/PER/927/P/E26/DIM 6/1FB T20

Philips A-shape LED lamps are the LED alternative to standard incandescents. It provides beautiful light and dependable performance you expect from LED at an affordable price.


Product data

General information		Power Factor (Nom)	
Base	E26 [Single Contact Medium Screw]		0.7
EU RoHS compliant	Yes	Voltage (Nom)	120 V
Nominal Lifetime (Nom)	15000 h	Temperature	
Switching Cycle	50000	T-Case Maximum (Nom)	185 °F
Light technical		Controls and dimming	
Color Code	927 [CCT of 2700K]	Dimmable	Yes
Beam Angle (Nom)	250 °	Mechanical and housing	
Initial lumen (Nom)	1100 lm	Bulb Finish	Frosted
Color Designation	Warm White (WW)	Bulb Material	Plastic
Correlated Color Temperature (Nom)	2700 K	Bulb Shape	A19 (A19)
Luminous Efficacy (rated) (Nom)	90.00 lm/W	Approval and application	
Color Consistency	<4	Energy Consumption kWh/1000 h	- kWh
Color Rendering Index (Nom)	90	Energy Certifications	Energy Star
LLMF At End Of Nominal Lifetime (Nom)	70 %	Product data	
Operating and electrical		Order product name	12.2A19/PER/927/P/E26/DIM 6/1FB T20
Input Frequency	60 Hz	EAN/UPC - Product	046677561031
Power (Rated) (Nom)	12.2 W	Order code	561035
Lamp Current (Nom)	100 mA	Numerator - Quantity Per Pack	1
Wattage Equivalent	75 W	Numerator - Packs per outer box	6
Starting Time (Nom)	0.5 s		
Warm Up Time to 60% Light (Nom)	0.5 s		

A-Shape LED

Material Nr. (12NC)	929002385204
Net Weight (Piece)	0.132 lb



Dimensional drawing

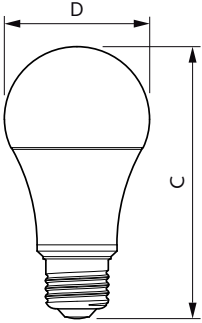

12.2A19/PER/927/P/E26/DIM 6/1FB T20


Product	D	C
12.2A19/PER/927/P/E26/DIM 6/1FB T20	2-3/8 in	4-7/16 in

Photometric data

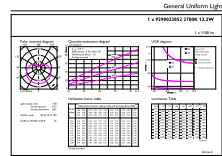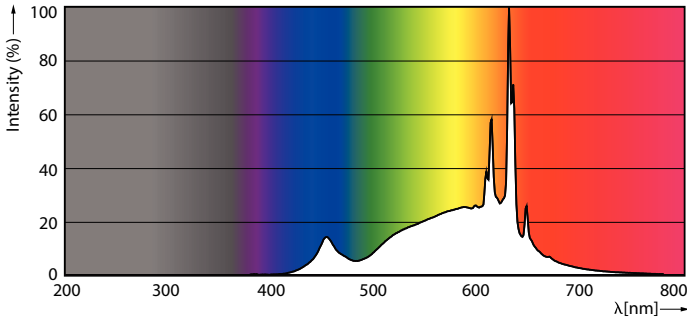

LEDbulb 12,2W A19 E26 927 FR


LEDbulb 12,2W A19 E26 927 FR

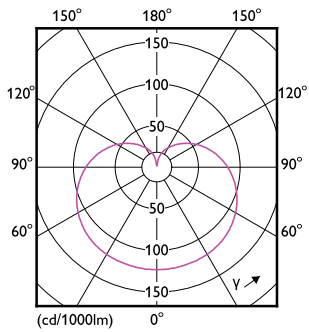

LEDbulb A19 12,2W E26 1100lm 927 FR

A-Shape LED

Lifetime

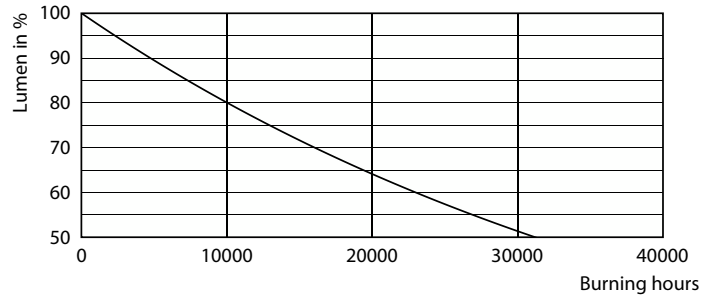

Life Expectancy Diagram

Lumen Maintenance Diagram

