

LED Party Bulbs

4A19/LED/RED/G/E26/ND 6/1BC

Philips A shape party lamps provided a bright light and color to a wide variety of applications. Ideal for special occasions, parties, and holidays.


Product data

General information	
Base	E26 [Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	20000
Light technical	
Color Code	Red
Color Designation	Red
Color Consistency	-
Color Rendering Index (Nom)	60
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	4 W
Lamp Current (Nom)	55 mA
Wattage Equivalent	40 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.4
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	122 °F

Controls and dimming	
Dimmable	No
Mechanical and housing	
Bulb Finish	Red
Bulb Material	Glass
Bulb Shape	A19 (A19)
Approval and application	
Energy Consumption kWh/1000 h	- kWh
Energy Certifications	No
Product data	
Order product name	4A19/LED/RED/G/E26/ND 6/1BC
EAN/UPC - Product	046677538200
Order code	538207
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	929001937003
Net Weight (Piece)	0.137 lb

LED Party Bulbs


Dimensional drawing

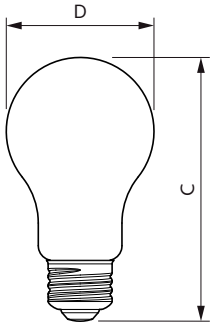


4A19/LED/RED/G/E26/ND 6/1BC

Product	D	C
4A19/LED/RED/G/E26/ND 6/1BC	2-3/8 in	4-3/16 in

Photometric data

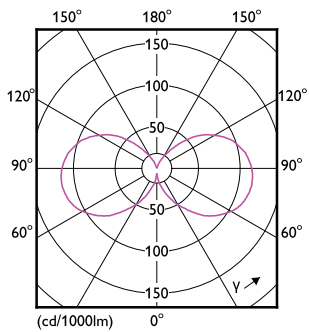


LEDbulb Color A19 4W E26

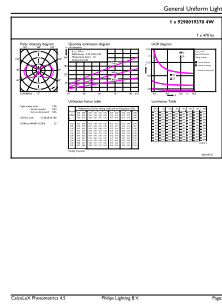


LEDbulb Color 4W A19 E26 Red

Lifetime

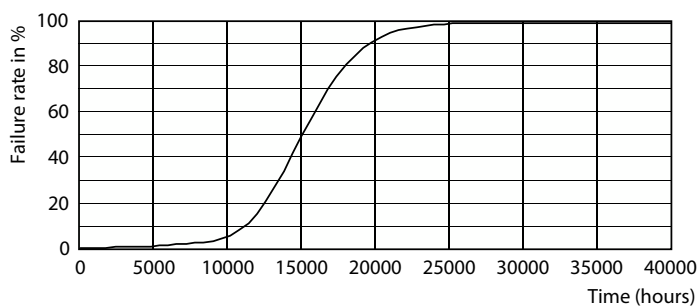

Life Expectancy Diagram

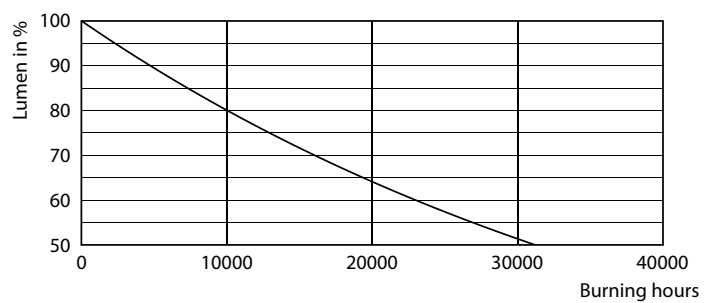

Lumen Maintenance Diagram

LED Party Bulbs

