



PL-C/T

8.5PL-C/T/COR/26H-827/IF8/P/4P/DIM 10/1

Philips PLED 4-pin & 2-pin lamps are an affordable LED solution to replace compact fluorescent lamps. The product provides a natural lighting effect for use in many lighting applications, and provides instant energy savings, making them an environmentally-friendly solution. Available as replacements for 13W, 26W and 32W compact fluorescent lamps.

Product data


General information		Power (Rated) (Nom)	
Base	G24Q [G24q]		8.5 W
EU RoHS compliant	Yes	Lamp Current (Max)	550 mA
Main Application	Industrial	Lamp Current (Min)	150 mA
Nominal Lifetime (Nom)	50000 h	Wattage Equivalent	26 W
Switching Cycle	50000	Starting Time (Nom)	0.5 s
Tier	CorePro	Warm Up Time to 60% Light (Nom)	0.5 s
Light technical		UL Type	Type A - works on ballast
Color Code	827 [CCT of 2700K]	Power Factor (Nom)	0.9
Beam Angle (Nom)	120 °	Voltage (Nom)	120 V
Initial lumen (Nom)	850 lm	Temperature	
Luminous Flux (Rated) (Nom)	850 lm	T-Ambient (Max)	113 °F
Color Designation	Warm White (WW)	T-Ambient (Min)	-4 °F
Correlated Color Temperature (Nom)	2700 K	T-Storage (Max)	149 °F
Luminous Efficacy (rated) (Nom)	100.00 lm/W	T-Storage (Min)	-40 °F
Color Consistency	<6	T-Case Maximum (Nom)	140 °F
Color Rendering Index (Nom)	82	Controls and dimming	
LLMF At End Of Nominal Lifetime (Nom)	70 %	Dimmable	Yes
Operating and electrical		Mechanical and housing	
Input Frequency	20000-100000 Hz	Bulb Finish	Frosted

PL-C/T

Bulb Material	Plastic
Product Length	7-7/8 in
Bulb Shape	Tube, single-ended
Approval and application	
Energy Saving Product	Yes
Approbation Marks	RoHS compliance UL certificate KEMA Keur certificate DLC compliance
Energy Consumption kWh/1000 h	- kWh
Energy Certifications	DLC Standard

Product data	
Order product name	8.5PL-C/T/COR/26H-827/IF8/P/4P/DIM 10/1
EAN/UPC - Product	046677458362
Order code	458364
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929001388004
Net Weight (Piece)	0.181 lb
Model Number	9290013880


Dimensional drawing

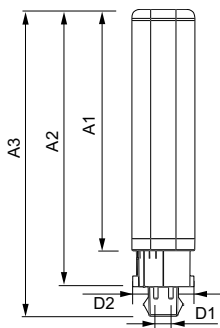

8.5PL-C/T/COR/26H-827/IF8/P/4P/DIM 10/1

Product	D1	D2	A1	A2	A3
8.5PL-C/T/COR/ 26H-827/IF8/P/4P/DIM 10/1	1 in	1-1/8 in	5-1/16 in	5-13/16 in	6-7/16 in


Photometric data

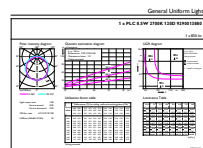

LEDtube PLC 100mm 9W G24Q GX24Q 827 850lm


LEDtube PLC 100mm 9W G24Q GX24Q 827 850lm

Photometric data

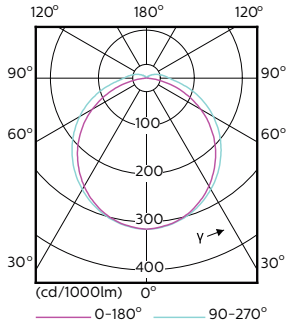


LEDtube PLC 100mm 9W G24Q GX24Q 827 850lm


Lifetime

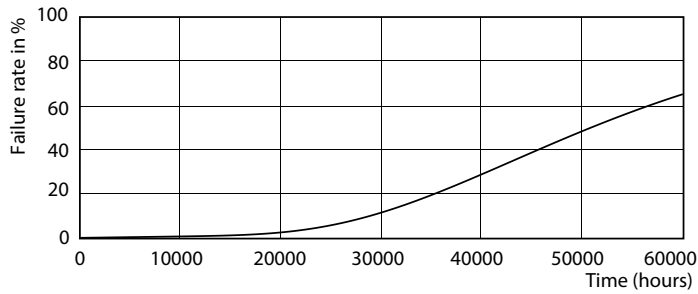


LEDtube PLC 100mm 9W G24Q GX24Q 827 850lm

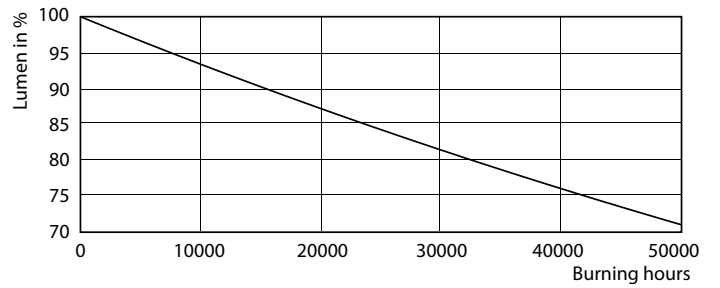

 LEDtube PLC 100mm 9W G24Q GX24Q 827 850lm




LEDtube PLC 100mm 9W G24Q GX24Q 827 850lm

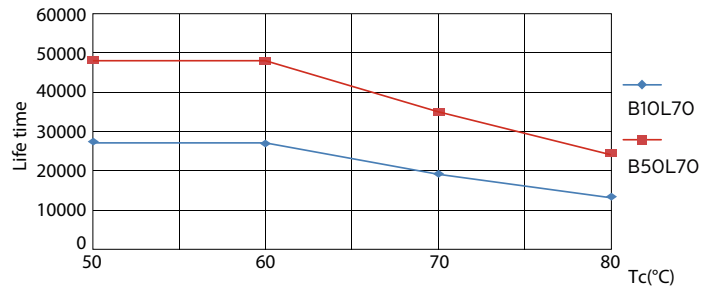

LEDtube PLC 100mm 9W G24Q GX24Q 827 850lm

PL-C/T

Lifetime

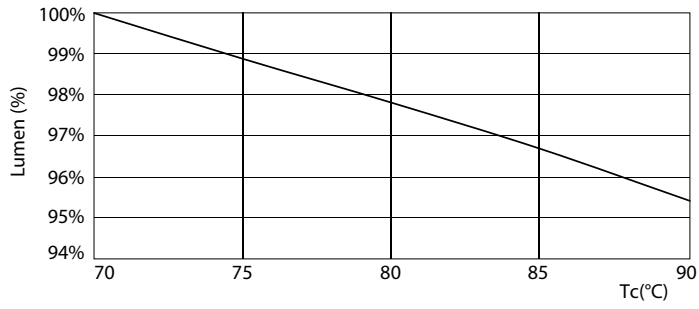

LEDtube PLC 100mm 9W G24Q GX24Q 827 850lm

