



A-Shape LED

12.2A19/LED/950/FR/P/E26/ND/T20 6/1FB

Philips A-shape LED lamps are the LED alternative to standard incandescents. It provides beautiful light and dependable performance you expect from LED at an affordable price.

Product data

General information	
Base	E26 [Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	11000 h
Switching Cycle	50000
Tier	CorePro

Light technical	
Color Code	950 [CCT of 5000K]
Beam Angle (Nom)	250 °
Initial lumen (Nom)	1100 lm
Color Designation	Daylight
Correlated Color Temperature (Nom)	5000 K
Luminous Efficacy (rated) (Nom)	90.00 lm/W
Color Consistency	<4
Color Rendering Index (Nom)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %

Operating and electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	12.2 W
Lamp Current (Nom)	98 mA
Wattage Equivalent	75 W
Starting Time (Nom)	0.5 s

Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.7
Voltage (Nom)	120 V

Temperature	
T-Case Maximum (Nom)	185 °F

Controls and dimming	
Dimmable	No

Mechanical and housing	
Bulb Finish	Frosted
Bulb Material	Plastic
Bulb Shape	A19 (A19)


Approval and application	
Energy Certifications	No

Product data	
Order product name	12.2A19/LED/950/FR/P/E26/ND/T20 6/1FB
EAN/UPC - Product	046677571665
Order code	571661
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6

A-Shape LED

Material Nr. (12NC)	929003020704
Net Weight (Piece)	0.121 lb


Dimensional drawing

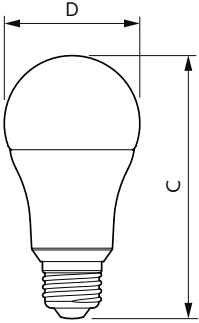


12.2A19/LED/950/FR/P/E26/ND/T20 6/1FB

Product	D	C
12.2A19/LED/950/FR/P/E26/ND/T20 6/1FB	2-3/8 in	4-5/8 in

Photometric data

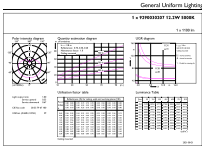


General Lighting Luminaire 11 Page 11

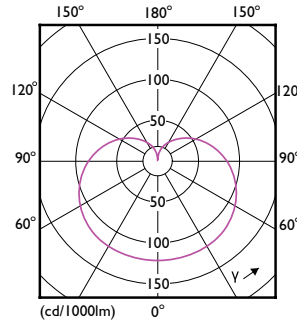

LEDbulb T20 12,2W A19 E26 950 FR 1-GUL



LEDbulb T20 A19 12,2W E26 950 FR-LDD

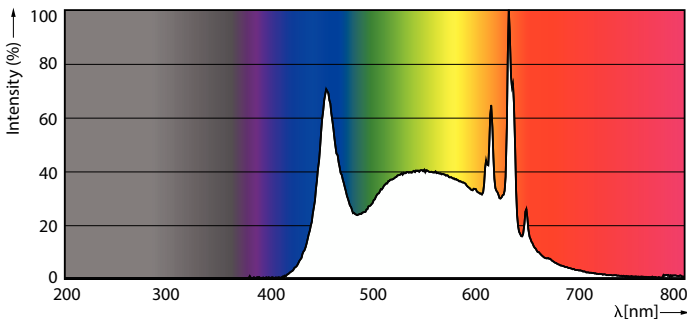

LEDbulb T20 12,2W A19 E26 950 FR-POC

A-Shape LED

Lifetime

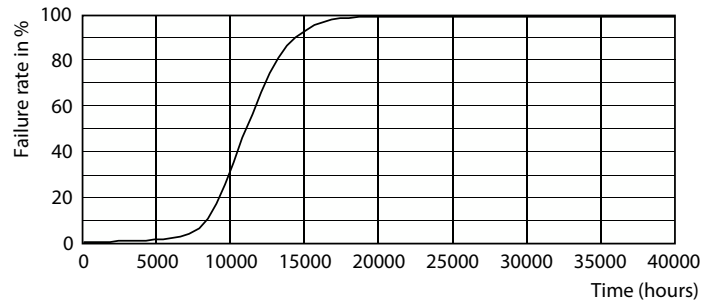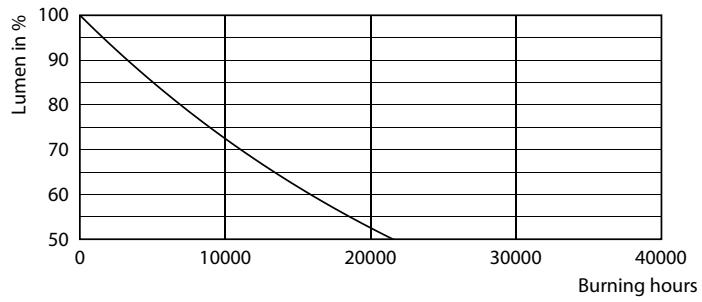

Lumen Maintenance Diagram

Life Expectancy Diagram

