



A-Shape LED

12.2A19/LED/927/FR/P/E26/ND/T20 6/1FB

Philips A-shape LED lamps are the LED alternative to standard incandescents. It provides beautiful light and dependable performance you expect from LED at an affordable price.

Product data

| General information | |
|------------------------|------------------------------------|
| Base | E26 [Single Contact Medium Screw] |
| EU RoHS compliant | Yes |
| Nominal Lifetime (Nom) | 11000 h |
| Switching Cycle | 50000 |
| Tier | CorePro |

| Light technical | |
|---------------------------------------|---------------------|
| Color Code | 927 [CCT of 2700K] |
| Beam Angle (Nom) | 250 ° |
| Initial lumen (Nom) | 1100 lm |
| Color Designation | Warm White (WW) |
| Correlated Color Temperature (Nom) | 2700 K |
| Luminous Efficacy (rated) (Nom) | 90.00 lm/W |
| Color Consistency | <4 |
| Color Rendering Index (Nom) | 90 |
| LLMF At End Of Nominal Lifetime (Nom) | 70 % |

| Operating and electrical | |
|--------------------------|--------|
| Input Frequency | 60 Hz |
| Power (Rated) (Nom) | 12.2 W |
| Lamp Current (Nom) | 98 mA |
| Wattage Equivalent | 75 W |
| Starting Time (Nom) | 0.5 s |

| | |
|---------------------------------|-------|
| Warm Up Time to 60% Light (Nom) | 0.5 s |
| Power Factor (Nom) | 0.7 |
| Voltage (Nom) | 120 V |

| Temperature | |
|----------------------|--------|
| T-Case Maximum (Nom) | 185 °F |

| Controls and dimming | |
|----------------------|----|
| Dimmable | No |

| Mechanical and housing | |
|------------------------|-----------|
| Bulb Finish | Frosted |
| Bulb Material | Plastic |
| Bulb Shape | A19 (A19) |


| Approval and application | |
|--------------------------|----|
| Energy Certifications | No |

| Product data | |
|---------------------------------|---------------------------------------|
| Order product name | 12.2A19/LED/927/FR/P/E26/ND/T20 6/1FB |
| EAN/UPC - Product | 046677571641 |
| Order code | 571646 |
| Numerator - Quantity Per Pack | 1 |
| Numerator - Packs per outer box | 6 |

A-Shape LED

| | |
|---------------------|--------------|
| Material Nr. (12NC) | 929003020504 |
| Net Weight (Piece) | 0.121 lb |


Dimensional drawing

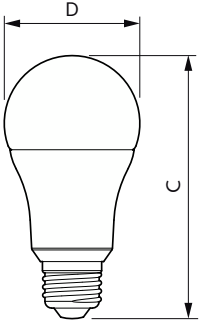


12.2A19/LED/927/FR/P/E26/ND/T20 6/1FB

| Product | D | C |
|---------------------------------------|----------|----------|
| 12.2A19/LED/927/FR/P/E26/ND/T20 6/1FB | 2-3/8 in | 4-5/8 in |

Photometric data

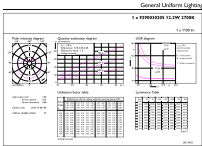


General Lighting Luminaire

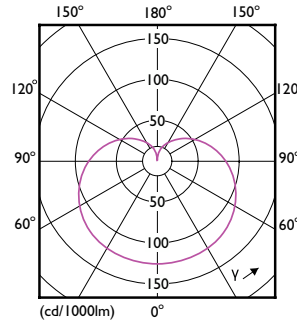

LEDbulb T20 12,2W A19 E26 927 FR 1-GUL



LEDbulb T20 A19 12,2W E26 927 FR-LDD

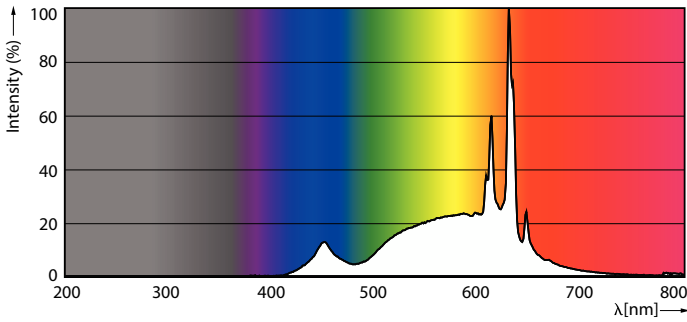

LEDbulb T20 12,2W A19 E26 927 FR-POC

A-Shape LED

Lifetime

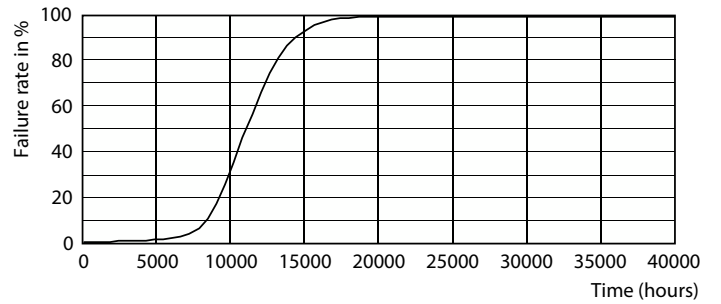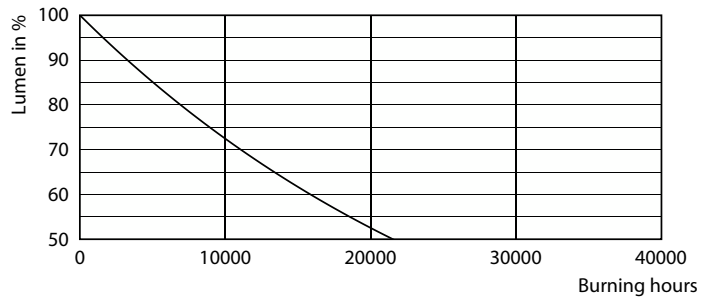

Lumen Maintenance Diagram

Life Expectancy Diagram

