



A-Shape LED

12.2A19/PER/940/P/E26/DIM 6/1FB T20

Philips A-shape LED lamps are the LED alternative to standard incandescents. It provides beautiful light and dependable performance you expect from LED at an affordable price.


Product data

General information		Power Factor (Nom)	
Base	E26 [Single Contact Medium Screw]		0.7
EU RoHS compliant	Yes	Voltage (Nom)	
Nominal Lifetime (Nom)	15000 h		120 V
Switching Cycle	50000	Temperature	
		T-Case Maximum (Nom)	185 °F
Light technical		Controls and dimming	
Color Code	940 [CCT of 4000K]	Dimmable	Yes
Beam Angle (Nom)	250 °	Mechanical and housing	
Initial lumen (Nom)	1100 lm	Bulb Finish	Frosted
Color Designation	Cool White (CW)	Bulb Material	Plastic
Correlated Color Temperature (Nom)	4000 K	Bulb Shape	A19 (A19)
Luminous Efficacy (rated) (Nom)	90.00 lm/W	Approval and application	
Color Consistency	<4	Energy Consumption kWh/1000 h	- kWh
Color Rendering Index (Nom)	90	Energy Certifications	Energy Star
LLMF At End Of Nominal Lifetime (Nom)	70 %	Product data	
Operating and electrical		Order product name	12.2A19/PER/940/P/E26/DIM 6/1FB T20
Input Frequency	60 Hz	EAN/UPC - Product	046677561055
Power (Rated) (Nom)	12.2 W	Order code	561050
Lamp Current (Nom)	100 mA	Numerator - Quantity Per Pack	1
Wattage Equivalent	75 W	Numerator - Packs per outer box	6
Starting Time (Nom)	0.5 s		
Warm Up Time to 60% Light (Nom)	0.5 s		

A-Shape LED

Material Nr. (12NC)	929002385404
Net Weight (Piece)	0.132 lb


Dimensional drawing

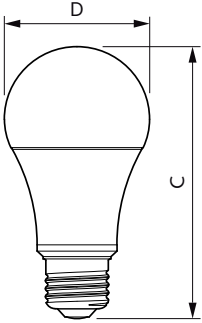


12.2A19/PER/940/P/E26/DIM 6/1FB T20

Product	D	C
12.2A19/PER/940/P/E26/DIM 6/1FB T20	2-3/8 in	4-7/16 in


Photometric data

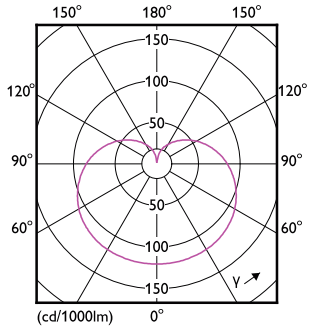

LEDbulb A19 12,2W E26 1100lm 930 FR

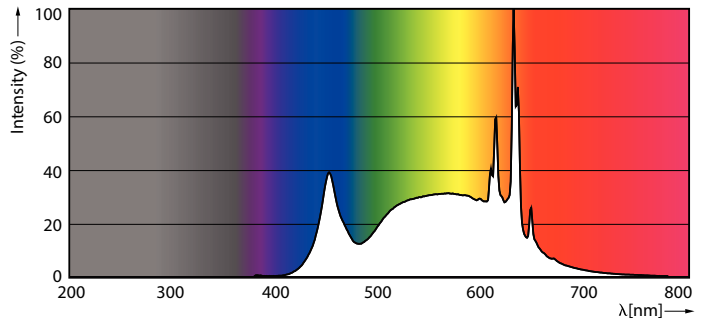


LEDbulb 12,2W A19 E26 940 FR

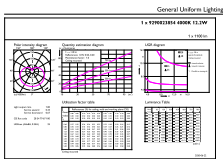

LEDbulb 12,2W A19 E26 940 FR

A-Shape LED

Lifetime

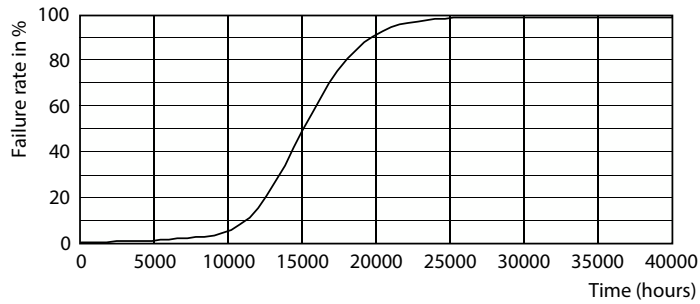

Life Expectancy Diagram

Lumen Maintenance Diagram

