

# A-Shape LED

## 8A19/PER/927-922/CL/G/E26/WGX 1FB T20

Philips A-shape LED lamps are the LED alternative to standard incandescents. It provides beautiful light and dependable performance you expect from LED at an affordable price.

### Product data

General information	
Base	E26 [ Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	20000X

Light technical	
Color Code	927-922 [ CCT of 2700K-2200K]
Beam Angle (Nom)	300 °
Initial lumen (Nom)	800 lm
Color Designation	Warm Glow(WG)
Correlated Color Temperature (Nom)	2700 2200 K
Luminous Efficacy (rated) (Nom)	100.00 lm/W
Color Consistency	<4
Color Rendering Index (Nom)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %

Operating and electrical	
Input Frequency	50 to 60 Hz
Power (Rated) (Nom)	8 W
Lamp Current (Nom)	85 mA
Wattage Equivalent	60 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s

Power Factor (Nom)	0.75
Voltage (Nom)	120 V

Temperature	
T-Case Maximum (Nom)	140 °F

Controls and dimming	
Dimmable	Yes

Mechanical and housing	
Bulb Finish	Clear
Bulb Material	Glass
Bulb Shape	A19 (A19)


Approval and application	
Energy Consumption kWh/1000 h	- kWh
Energy Certifications	Energy Star

Product data	
Order product name	8A19/PER/927-922/CL/G/E26/WGX 1FB T20
EAN/UPC - Product	046677549497
Order code	549493
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6

A-Shape LED

Material Nr. (12NC)	929001969604
Net Weight (Piece)	0.066 lb



Dimensional drawing

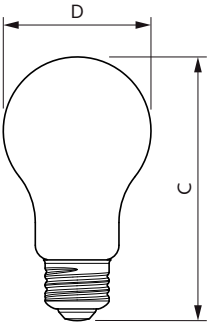

8A19/PER/927-922/CL/G/E26/WGX 1FB T20


Product	D	C
8A19/PER/927-922/CL/G/E26/WGX 1FB T20	2-3/8 in	4-1/4 in

Photometric data

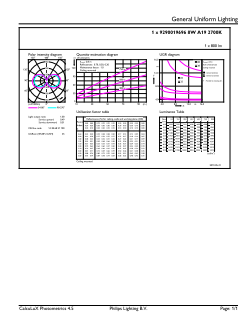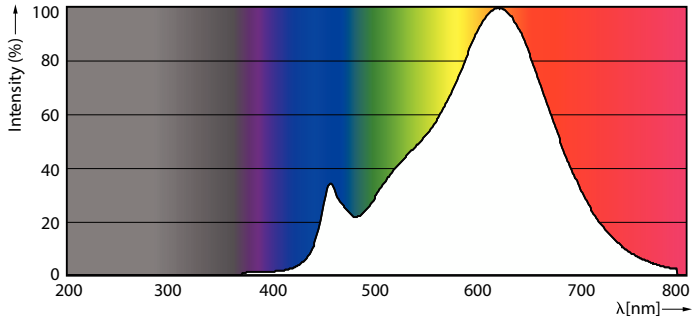

Spectral Power Distribution Colour

LEDbulb 60W E26 A19 927 CL

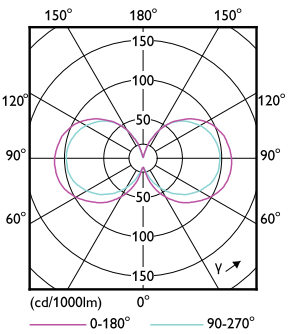

LEDbulb 927 CL

A-Shape LED

Lifetime



Life Expectancy Diagram



Lumen Maintenance Diagram

