



A-Shape LED

12.2A19/LED/930/FR/P/E26/ND/T20 6/1FB

Philips A-shape LED lamps are the LED alternative to standard incandescents. It provides beautiful light and dependable performance you expect from LED at an affordable price.


Product data

General information		Warm Up Time to 60% Light (Nom)	
Base	E26 [Single Contact Medium Screw]	Warm Up Time to 60% Light (Nom)	0.5 s
EU RoHS compliant	Yes	Power Factor (Nom)	0.7
Nominal Lifetime (Nom)	11000 h	Voltage (Nom)	120 V
Switching Cycle	50000	Temperature	
Tier	CorePro	T-Case Maximum (Nom)	185 °F
Light technical		Controls and dimming	
Color Code	930 [CCT of 3000K]	Dimmable	No
Beam Angle (Nom)	250 °	Mechanical and housing	
Initial lumen (Nom)	1100 lm	Bulb Finish	Frosted
Color Designation	White (WH)	Bulb Material	Plastic
Correlated Color Temperature (Nom)	3000 K	Bulb Shape	A19 (A19)
Luminous Efficacy (rated) (Nom)	90.00 lm/W	Approval and application	
Color Consistency	<4	Energy Certifications	No
Color Rendering Index (Nom)	90	Product data	
LLMF At End Of Nominal Lifetime (Nom)	70 %	Order product name	12.2A19/LED/930/FR/P/E26/ND/T20 6/1FB
Operating and electrical		EAN/UPC - Product	046677571658
Input Frequency	60 Hz	Order code	571653
Power (Rated) (Nom)	12.2 W	Numerator - Quantity Per Pack	1
Lamp Current (Nom)	98 mA	Numerator - Packs per outer box	6
Wattage Equivalent	75 W		
Starting Time (Nom)	0.5 s		

A-Shape LED

Material Nr. (12NC)	929003020604
Net Weight (Piece)	0.121 lb


Dimensional drawing

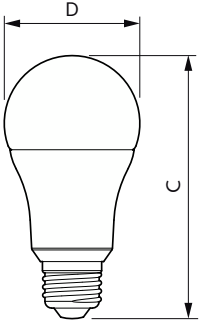


12.2A19/LED/930/FR/P/E26/ND/T20 6/1FB

Product	D	C
12.2A19/LED/930/FR/P/E26/ND/T20 6/1FB	2-3/8 in	4-5/8 in


Photometric data

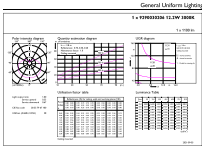

LEDbulb T20 12,2W A19 E26 930 FR 1-GUL

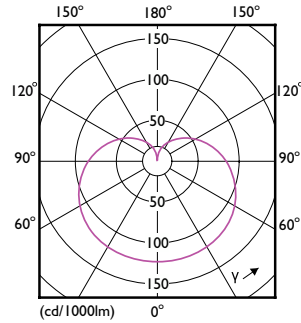



LEDbulb T20 A19 12,2W E26 930 FR-LDD

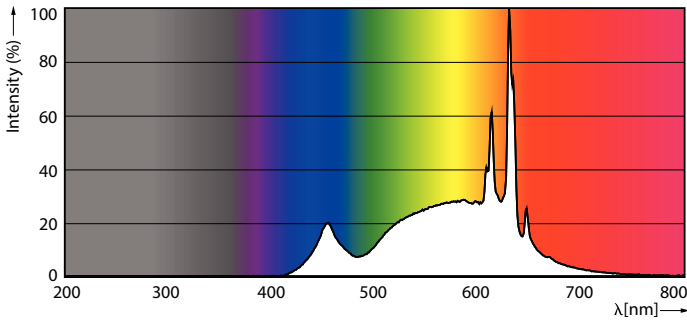

LEDbulb T20 12,2W A19 E26 930 FR-POC

A-Shape LED

Lifetime

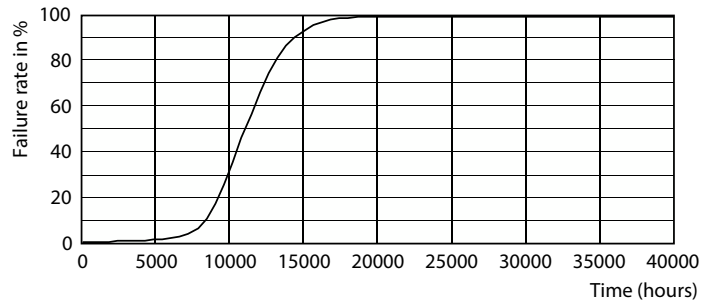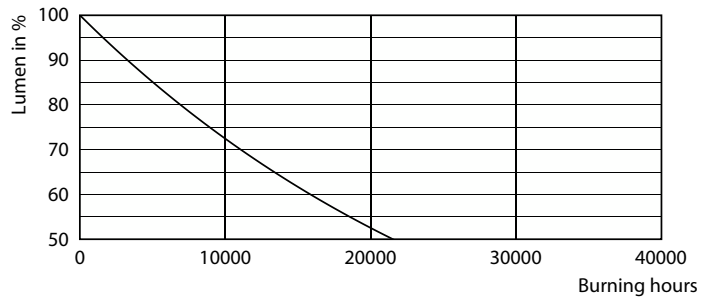

Lumen Maintenance Diagram

Life Expectancy Diagram

