



LED Party Bulbs

8A19/LED/RED/P/ND 120V 4/1FB

Philips A shape party lamps provided a bright light and color to a wide variety of applications. Ideal for special occasions, parties, and holidays.

Product data


General information	
Base	E26 [Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	10950 h
Switching Cycle	20000X
Light technical	
Beam Angle (Nom)	120 °
Color Consistency	-
Color Rendering Index (Nom)	-
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	8 W
Lamp Current (Nom)	115 mA
Wattage Equivalent	40 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.5
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	176 °F

Controls and dimming	
Dimmable	No
Mechanical and housing	
Bulb Finish	Frosted
Bulb Material	Plastic
Bulb Shape	A19 (A19)
Approval and application	
Energy Consumption kWh/1000 h	- kWh
Energy Certifications	No

Product data	
Order product name	8A19/LED/RED/P/ND 120V 4/1FB
EAN/UPC - Product	046677463274
Order code	463273
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	4
Material Nr. (12NC)	929001997805
Net Weight (Piece)	0.132 lb

LED Party Bulbs


Dimensional drawing

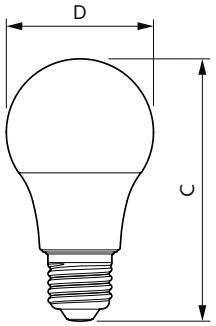


8A19/LED/RED/P/ND 120V 4/1FB

Product	D	C
8A19/LED/RED/P/ND 120V 4/1FB	2-3/8 in	4-1/4 in


Photometric data

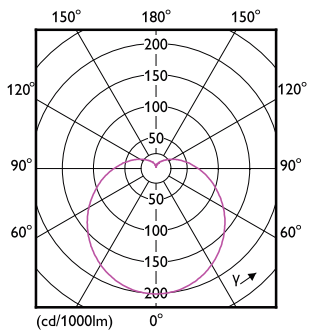

LEDbulb Color P A19 8W E26 Red

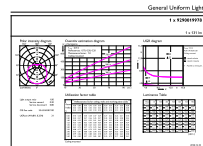


LEDbulb Color P 8W A19 E26 Red

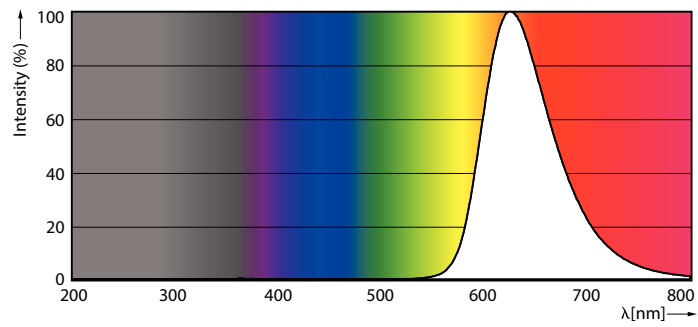


LEDbulb Color P 8W A19 E26 Red

LED Party Bulbs

Lifetime

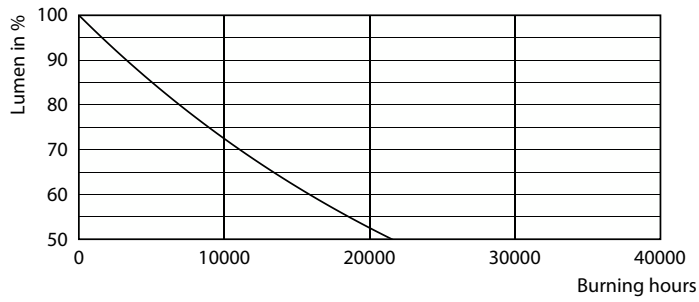

Lumen Maintenance Diagram

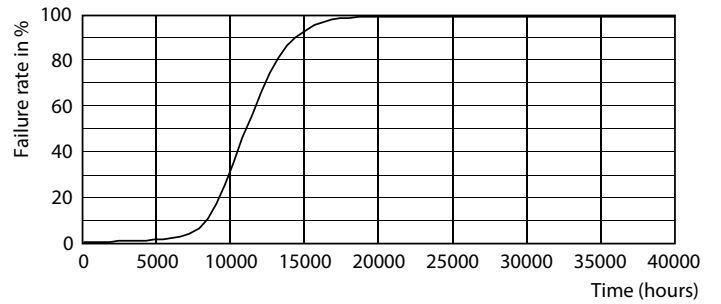

Life Expectancy Diagram

