



LED BA11

6.6BA11/PER/927-922/CL/G/E12/WGX T20

Philips LED BA11 candles offer energy saving ambiance with the elegant effect of incandescent candles. These designs provides light in an omnidirectional manner, giving lighting designers a long life alternative to standard incandescent sources.

Product data

General information	
Base	E12 [Candelabra Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	20000
Light technical	
Color Code	927-922 [CCT of 2700K-2200K]
Initial lumen (Nom)	600 lm
Color Designation	Warm Glow(WG)
Correlated Color Temperature (Nom)	2700 2200 K
Luminous Efficacy (rated) (Nom)	90.00 lm/W
Color Consistency	<4
Color Rendering Index (Nom)	90
LLMF At End Of Nominal Lifetime (Nom)	0.7 %
Operating and electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	6.6 W
Lamp Current (Nom)	75 mA
Wattage Equivalent	75 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.7


Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	140 °F
Controls and dimming	
Dimmable	Yes
Mechanical and housing	
Bulb Finish	Clear
Bulb Material	Glass
Bulb Shape	BA11 [BA 35mm]
Approval and application	
Energy Consumption kWh/1000 h	- kWh
Energy Certifications	No

Product data	
Order product name	6.6BA11/PER/927-922/CL/G/E12/WGX T20
EAN/UPC - Product	046677557478
Order code	557470
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	929002295704

LED BA11

Net Weight (Piece)	0.031 lb
--------------------	----------


Dimensional drawing

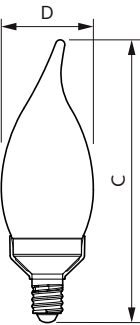


6.6BA11/PER/927-922/CL/G/E12/WGX T20

Product	D	C
6.6BA11/PER/927-922/CL/G/E12/WGX T20	1-3/8 in	4-3/8 in

Photometric data

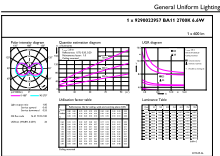


General Uniform Lighting

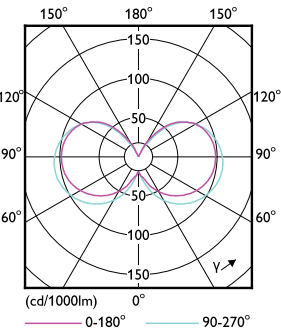

LEDbulb BA11 CL


LEDbulb 75W E12 BA11 927 CL

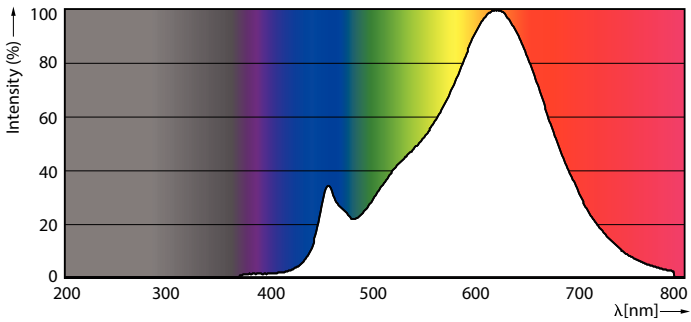


LEDbulb BA11 927 CL

LED BA11

Lifetime

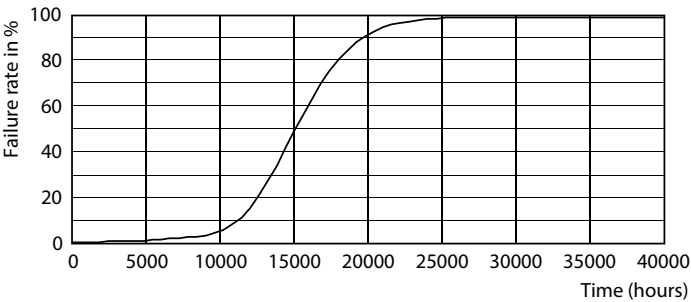

Life Expectancy Diagram

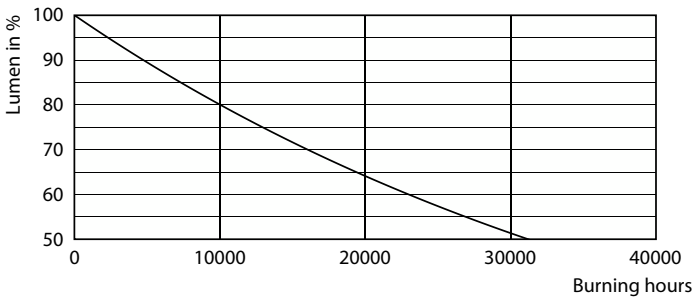

Lumen Maintenance Diagram

