



BUS Cables

Profibus SK fixed installed Indoor + Outdoor

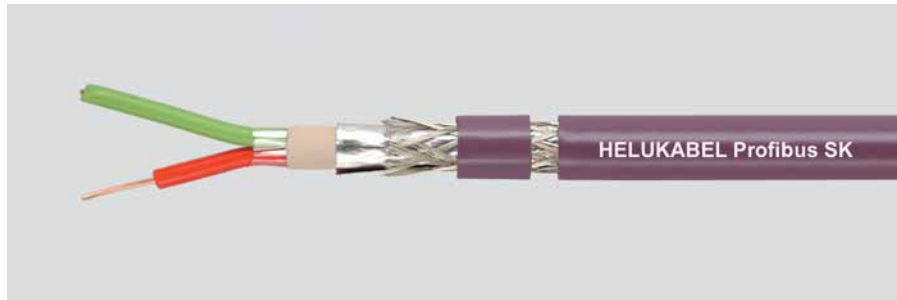

PVC + PE

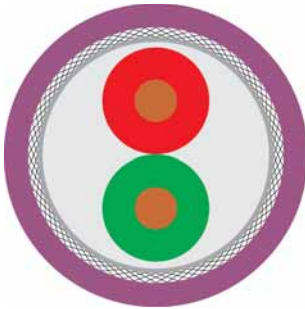

Type

Cable structure

Inner conductor diameter:
Core insulation:
Core colours:
Stranding element:
Separator:
Inner sheath material:
Shielding 1:
Total shielding:
Outer sheath material:
Cable external diameter:
Outer sheath colour:

Fixed installation, indoor 1x2x0.64 mm

Copper, bare (AWG 22/1)
Foam-skin-PE
rd, gn
Double core
Polyester foil over stranded bundle
PVC
Al-Foil
Cu braid, tinned
PVC
app. 8,0 mm ± 0,4 mm
Violet similar to RAL 4001

Fixed installation, outdoor 1x2x0.64 mm

Copper, bare (AWG 22/1)
Foam-skin-PE
rd, gn
Double core
Polyester foil over stranded bundle
PVC
Al-Foil
Cu braid, tinned
PE
app. 8,0 mm ± 0,4 mm
Black similar to RAL 9005

Electrical data

Characteristic impedance:
Conductor resistance, max.:
Insulation resistance, min.:
Loop resistance:
Mutual capacitance:
Test voltage:
Attenuation:

150 Ohm ± 10 %
55 Ohm/km
1 GOhm x km
110 Ohm/km max.
35 nF/km nom.
1,5 kV
9,6 kHz < 2,5 dB/km
38,4 kHz < 4,0 dB/km
4,0 MHz < 22,0 dB/km
16,0 MHz < 42,0 dB/km

150 Ohm ± 10 %
55 Ohm/km
1 GOhm x km
110 Ohm/km max.
35 nF/km nom.
1,5 kV
9,6 kHz < 2,5 dB/km
38,4 kHz < 4,0 dB/km
4 MHz < 22,0 dB/km
16 MHz < 42,0 dB/km

Technical data

Weight:
bending radius, repeated:
Operating temperature range min.:
Operating temperature range max.:
Caloric load, approx. value:
Copper weight:

app. 79 kg/km
120 mm
-40°C
+80°C
1,068 MJ/m
24,00 kg/km

app. 65 kg/km
120 mm
-20°C
+70°C
1,451 MJ/m
24,00 kg/km

Norms

Applicable standards:

Profibus acc. to DIN 19245 T3 and EN50170
Flame-retardant acc. to IEC 60332-3
CMG 75°C or CL3 or AWM 21694 600V
CSA FT 4

Profibus acc. to DIN 19245 T3 and EN50170

UL Style:

CSA standard:

-

-

Application

HELUKABEL® Profibus SK Indoor + Outdoor have a special structure for processing with the Fast Connect Stripping Tool from Siemens. The indoor version is used for normal requirements in fixed installation applications in equipment; the Outdoor version is used in open-air applications, i.e. can withstand wind, weather and sun (not for burial directly in the ground).

Part no.

81903, Profibus SK

81904, Profibus SK

Dimensions and specifications may be changed without prior notice.