

T8

35T8/96-4000 IF FA8 10/1

Our TLEDs are available in InstantFit (Type A / Type C) or MainsFit (Ballast bypass / Type B) versions. The InstantFit lamps work on a broad variety of ballasts and LED drivers. Only InstantFit has over 15,000 lamp & ballast combinations delivering even light output, energy savings and a long lifetime. Our MainsFit products feature a double-ended design, simplifying installation while a proprietary safety circuit minimizes a shock risk. Lamp sizes range from 2-foot to 8-foot and U-bend with a variety of lumen outputs.

Product data

General information		Power (Rated) (Nom)	
Base	FA8 [FA8]		35 W
EU RoHS compliant	Yes	Lamp Current (Max)	260 mA
Nominal Lifetime (Nom)	50000 h	Lamp Current (Min)	160 mA
Switching Cycle	50000	Wattage Equivalent	96 W
Tier	CorePro	Warm Up Time to 60% Light (Nom)	0.5 s
		UL Type	Type A - works on ballast
		Power Factor (Nom)	0.9
		Voltage (Nom)	280-410 V
Light technical		Temperature	
Color Code	841 [CCT of 4100K (841)]	T-Ambient (Max)	113 °F
Beam Angle (Nom)	180 °	T-Ambient (Min)	-4 °F
Initial lumen (Nom)	4200 lm	T-Ambient (Min)-DUP(do not use)	-4 °F
Color Designation	Cool White (CW)	T-Storage (Max)	149 °F
Correlated Color Temperature (Nom)	4000 K	T-Storage (Min)	-40 °F
Luminous Efficacy (rated) (Nom)	120.00 lm/W	T-Case Maximum (Nom)	113 °F
Color Consistency	<6		
Color Rendering Index (Nom)	82	Controls and dimming	
LLMF At End Of Nominal Lifetime (Nom)	70 %	Dimmable	No
Operating and electrical			
Input Frequency	50000-64000 Hz		

T8

Mechanical and housing

Bulb Finish	Frosted
Bulb Material	Plastic
Product Length	96 in
Bulb Shape	Tube, double-ended


Approval and application

Energy Saving Product	Yes
Approbation Marks	UL certificate
Energy Consumption kWh/1000 h	- kWh

Product data

Order product name	35T8/96-4000 IF FA8 10/1
EAN/UPC - Product	046677472580
Order code	469254
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929001314604
Net Weight (Piece)	1.19 lb
Model Number	9290013146


Dimensional drawing

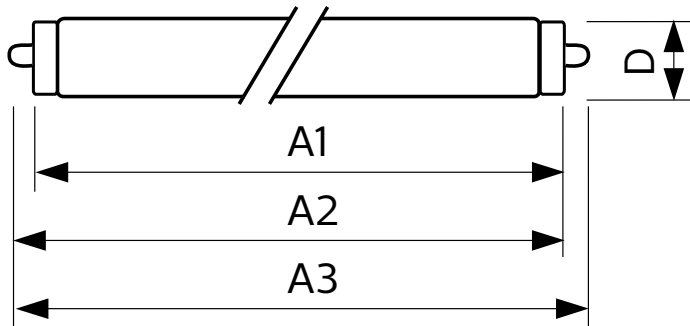


35T8/96-4000 IF FA8 10/1

Product	D	A1	A2	A3
35T8/96-4000 IF FA8 10/1	1-1/8 in	93-3/16 in	93-9/16 in	93-7/8 in

Photometric data

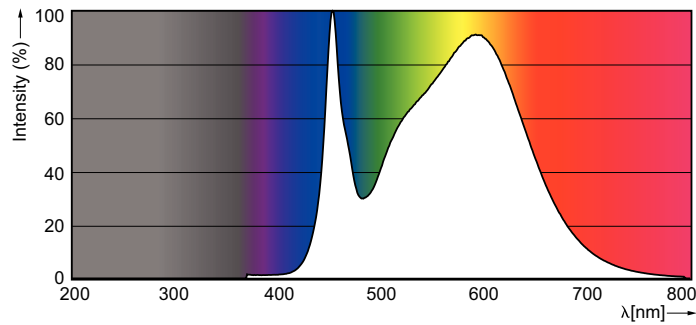


TLED Ess 35W FA8 840 4200lm T8

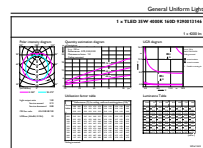

TLED Ess 35W FA8 840 4200lm T8



T8

Photometric data

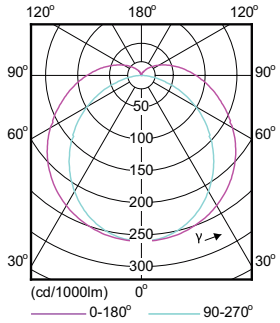

TLED Ess 35W FA8 840 4200lm T8

 Lifetime

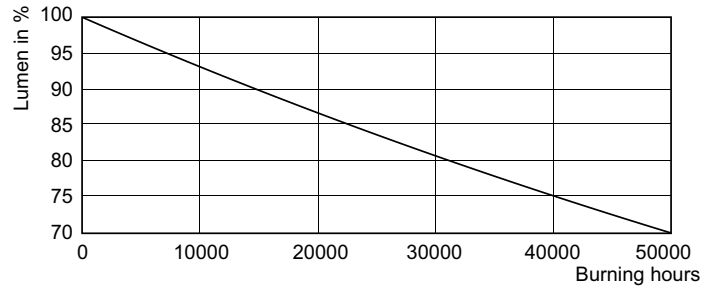

TLED Ess 35W FA8 T8 IF

TLED Ess 35W FA8 T8 IF

