



# A-Shape LED

## 16.6A19/LED/950/FR/P/E26/ND/T20 6/1FB

Philips A-shape LED lamps are the LED alternative to standard incandescents. It provides beautiful light and dependable performance you expect from LED at an affordable price.


### Product data

General information		Warm Up Time to 60% Light (Nom)	
Base	E26 [ Single Contact Medium Screw]	0.5 s	
EU RoHS compliant	Yes	Power Factor (Nom)	0.7
Nominal Lifetime (Nom)	11000 h	Voltage (Nom)	120 V
Switching Cycle	50000	<b>Temperature</b>	
Tier	CorePro	T-Case Maximum (Nom)	194 °F
<b>Light technical</b>		<b>Controls and dimming</b>	
Color Code	950 [ CCT of 5000K]	Dimmable	No
Beam Angle (Nom)	250 °	<b>Mechanical and housing</b>	
Initial lumen (Nom)	1500 lm	Bulb Finish	Frosted
Color Designation	Daylight	Bulb Material	Plastic
Correlated Color Temperature (Nom)	5000 K	Bulb Shape	A19 (A19)
Luminous Efficacy (rated) (Nom)	90.00 lm/W	<b>Approval and application</b>	
Color Consistency	<4	Energy Certifications	No
Color Rendering Index (Nom)	90	<b>Product data</b>	
LLMF At End Of Nominal Lifetime (Nom)	70 %	Order product name	16.6A19/LED/950/FR/P/E26/ND/T20 6/1FB
<b>Operating and electrical</b>		EAN/UPC - Product	046677571696
Input Frequency	60 Hz	Order code	571695
Power (Rated) (Nom)	16.6 W	Numerator - Quantity Per Pack	1
Lamp Current (Nom)	118 mA	Numerator - Packs per outer box	6
Wattage Equivalent	100 W		
Starting Time (Nom)	0.5 s		

# A-Shape LED

Material Nr. (12NC)	929003021004
Net Weight (Piece)	0.121 lb


## Dimensional drawing

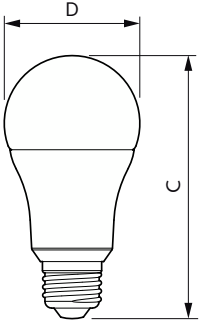


16.6A19/LED/950/FR/P/E26/ND/T20 6/1FB

Product	D	C
16.6A19/LED/950/FR/P/E26/ND/T20 6/1FB	2-3/8 in	4-5/8 in

## Photometric data

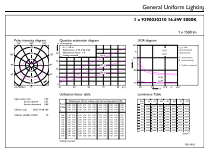


General Lighting Fixture

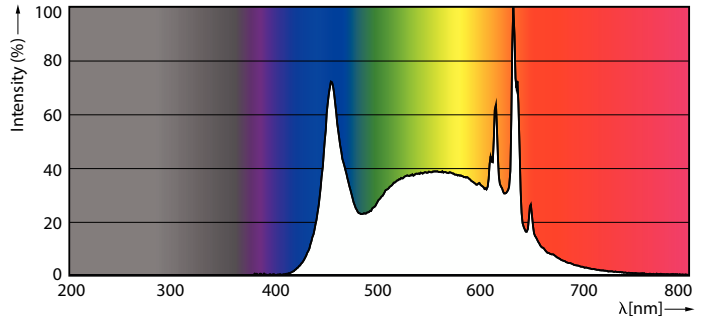

LEDbulb T20 16,6W A19 E26 950 FR 1-GUL


LEDbulb T20 16,6W A19 E26 950 FR-POC

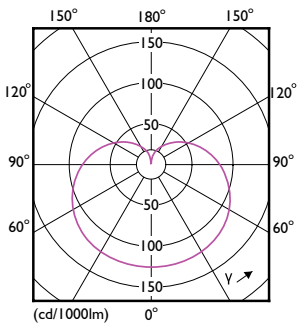

LEDbulb T20 A19 16,6W E26 950 FR-LDD

# A-Shape LED

## Lifetime

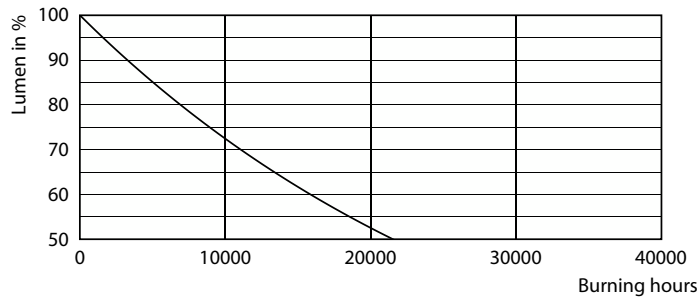

Lumen Maintenance Diagram

Life Expectancy Diagram

