

# LED A15

## 3.8A15/PER/927-922/CL/G/E26/WGX1FB T20

Philips A15 LED Lamps offer energy saving ambience with an elegant effect. Their unique design provides light in all directions, giving lighting designers a long life alternative to standard incandescent sources.

### Product data


General information	
Base	E26 [ Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	20000X
Light technical	
Color Code	927-922 [ CCT of 2700K-2200K]
Initial lumen (Nom)	350 lm
Color Designation	Warm Glow(WG)
Correlated Color Temperature (Nom)	2700 2200 K
Luminous Efficacy (rated) (Nom)	92.00 lm/W
Color Consistency	<4
Color Rendering Index (Nom)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and electrical	
Input Frequency	50 to 60 Hz
Power (Rated) (Nom)	3.8 W
Lamp Current (Nom)	42 mA
Wattage Equivalent	40 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.75

Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	122 °F
Controls and dimming	
Dimmable	Yes
Mechanical and housing	
Bulb Finish	Clear
Bulb Material	Glass
Bulb Shape	A15 [ A 15mm]
Approval and application	
Energy Consumption kWh/1000 h	- kWh
Energy Certifications	No
Product data	
Order product name	3.8A15/PER/927-922/CL/G/E26/WGX1FB T20
EAN/UPC - Product	046677549381
Order code	549386
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929002208304

# LED A15

Net Weight (Piece) 0.044 lb


## Dimensional drawing

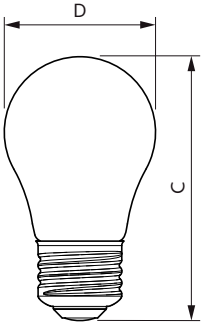


3.8A15/PER/927-922/CL/G/E26/WGX1FB T20

Product	D	C
3.8A15/PER/927-922/CL/G/E26/WGX1FB T20	1-7/8 in	3-7/16 in


## Photometric data

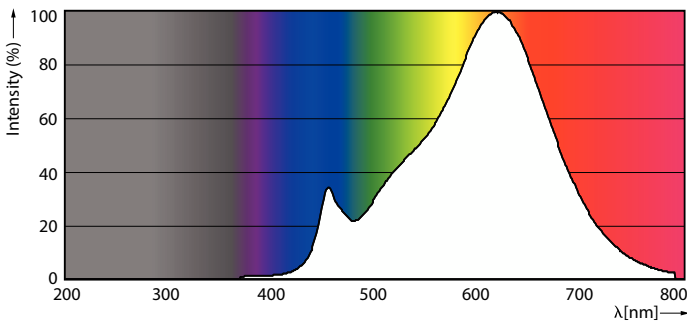

Spectral Power Distribution Colour

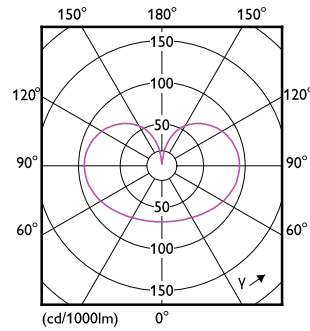

Light Distribution Diagram

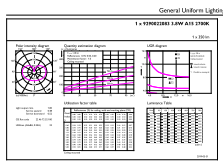

General Uniform Lighting Page 11

LEDbulb 40W E26 A15 927 CL

# LED A15

## Lifetime



Life Expectancy Diagram

Lumen Maintenance Diagram

