



LED BR30

7.2BR30/MAS/922-27/P/E26/WG 6/1FB

Philips BR30 LED lamps are the smart alternative to standard incandescent. The traditional lamp design can provide excellent dimming performance with spectacular energy savings. They provide the beautiful light and dependable performance you expect from LED at an economical price.

Product data

General information	
Base	E26 [Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	50000
Tier	MasterClass
Light technical	
Color Code	922-927 [CCT of 2200K-2700K]
Beam Angle (Nom)	90 °
Initial lumen (Nom)	650 lm
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	2200 2700 K
Luminous Efficacy (rated) (Nom)	90.00 lm/W
Color Consistency	<4
Color Rendering Index (Nom)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	7.2 W
Lamp Current (Nom)	85 mA
Wattage Equivalent	65 W


Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.7
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	167 °F
Controls and dimming	
Dimmable	Yes
Mechanical and housing	
Bulb Finish	Frosted
Bulb Material	Plastic
Bulb Shape	BR30
Approval and application	
Energy Consumption kWh/1000 h	- kWh
Energy Certifications	Energy Star
Product data	
Order product name	7.2BR30/MAS/922-27/P/E26/WG 6/1FB
EAN/UPC - Product	046677457044

LED BR30

Order code	457044
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	929001870334

Net Weight (Piece)	0.121 lb
--------------------	----------



Dimensional drawing

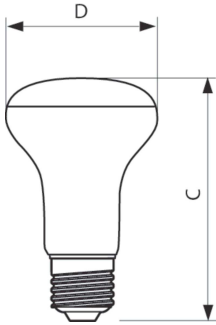

7.2BR30/PER/922-27/P/E26/WG 6/1FB


Product	D	C
7.2BR30/PER/922-27/P/E26/WG 6/1FB	3-3/4 in	5-1/4 in

Photometric data

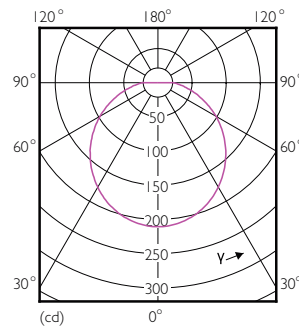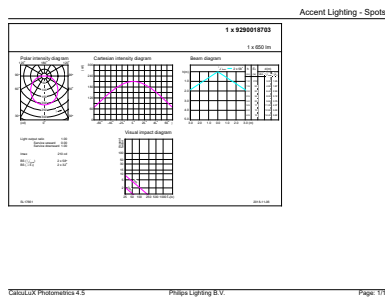

LED Bulbs BR30 120V 19-120W 1200lm 2700K E26 D



LED Bulbs BR30 120V 19-120W 1200lm 2700K E26 D

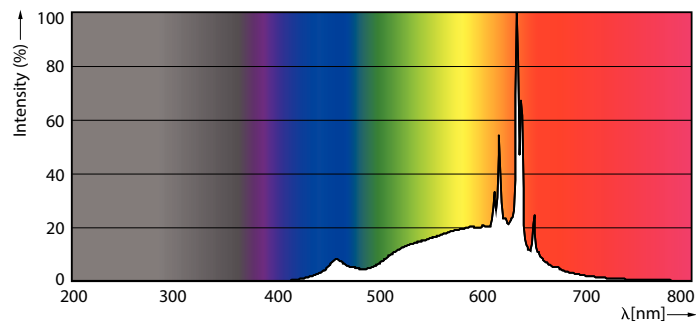

LED Bulbs BR30 120V 19-120W 1200lm 2700K E26 D

LED BR30

Lifetime

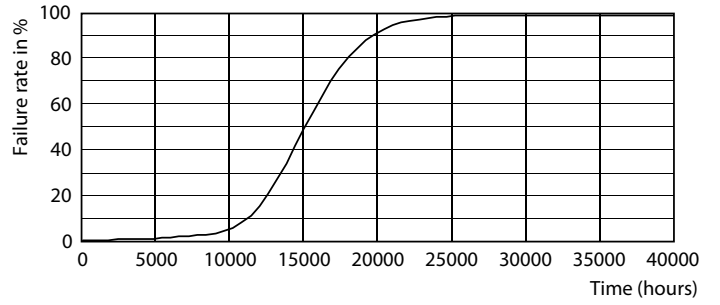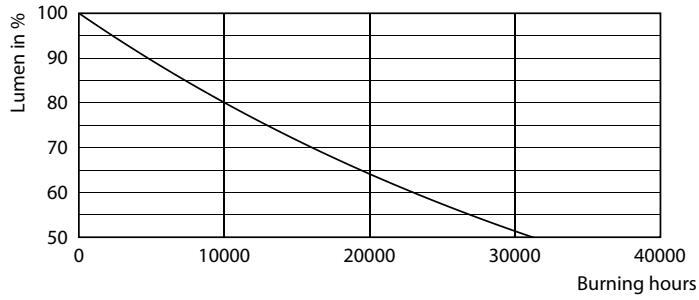

LEDBulbs BR30 120V 19-120W 1200lm 2700K E26 D

LEDBulbs BR30 120V 19-120W 1200lm 2700K E26 D

