



# A-Shape LED

## 12.2A19/PER/930/P/E26/DIM 6/1FB T20

Philips A-shape LED lamps are the LED alternative to standard incandescents. It provides beautiful light and dependable performance you expect from LED at an affordable price.


### Product data

General information		Power Factor (Nom)		0.7
Base	E26 [ Single Contact Medium Screw]	Voltage (Nom)		120 V
EU RoHS compliant	Yes	<b>Temperature</b>		
Nominal Lifetime (Nom)	15000 h	T-Case Maximum (Nom)		185 °F
Switching Cycle	50000	<b>Controls and dimming</b>		
<b>Light technical</b>		Dimmable		Yes
Color Code	930 [ CCT of 3000K]	<b>Mechanical and housing</b>		
Beam Angle (Nom)	250 °	Bulb Finish		Frosted
Initial lumen (Nom)	1100 lm	Bulb Material		Plastic
Color Designation	White (WH)	Bulb Shape		A19 (A19)
Correlated Color Temperature (Nom)	3000 K	<b>Approval and application</b>		
Luminous Efficacy (rated) (Nom)	90.00 lm/W	Energy Consumption kWh/1000 h		- kWh
Color Consistency	<4	Energy Certifications		Energy Star
Color Rendering Index (Nom)	90	<b>Product data</b>		
LLMF At End Of Nominal Lifetime (Nom)	70 %	Order product name		12.2A19/PER/930/P/E26/DIM 6/1FB T20
<b>Operating and electrical</b>		EAN/UPC - Product		046677561048
Input Frequency	60 Hz	Order code		561043
Power (Rated) (Nom)	12.2 W	Numerator - Quantity Per Pack		1
Lamp Current (Nom)	100 mA	Numerator - Packs per outer box		6
Wattage Equivalent	75 W			
Starting Time (Nom)	0.5 s			
Warm Up Time to 60% Light (Nom)	0.5 s			

# A-Shape LED

Material Nr. (12NC)	929002385304
Net Weight (Piece)	0.132 lb


## Dimensional drawing

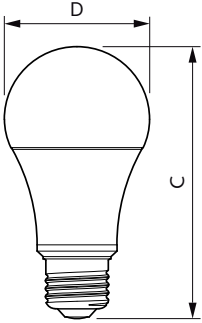


12.2A19/PER/930/P/E26/DIM 6/1FB T20

Product	D	C
12.2A19/PER/930/P/E26/DIM 6/1FB T20	2-3/8 in	4-7/16 in


## Photometric data

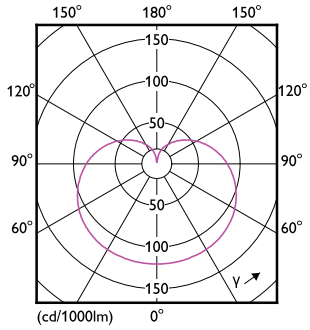

LEDbulb A19 12,2W E26 1100lm 930 FR

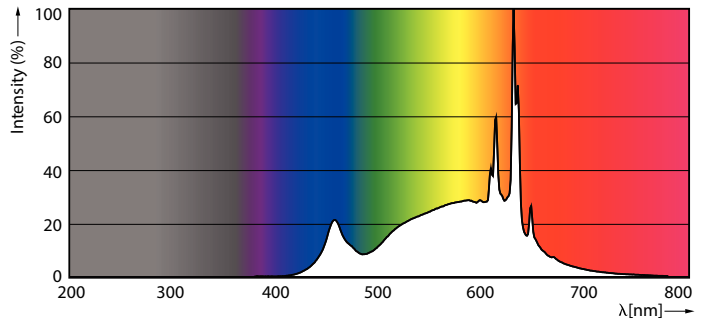

LEDbulb 12,2W A19 E26 930 FR

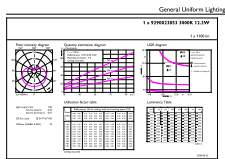

LEDbulb 12,2W A19 E26 930 FR

# A-Shape LED

## Lifetime



Life Expectancy Diagram

Lumen Maintenance Diagram

