



Party Spot

13.5PAR38/PER/BLUE/ND/ULW/G/120V 4/1FB

Philips 13.5-watt PAR 38s provide bright colorful light perfect for special occasions, parties and holidays. These PAR 38 lamps are available in up to four different colors and offer a festive touch to your home lighting. Brighten up your home and celebrate with color using these energy saving LED bulbs.

Product data


General information	
Base	E26 [Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	10950 h
Switching Cycle	50000X
Light technical	
Color Code	Blue
Initial lumen (Nom)	- lm
Color Designation	Blue
Luminous Efficacy (rated) (Nom)	90 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	-
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	13.5 W
Lamp Current (Nom)	165 mA
Wattage Equivalent	90 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.5

Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	156.2 °F
Controls and dimming	
Dimmable	No
Mechanical and housing	
Bulb Finish	Blue
Bulb Material	Glass
Bulb Shape	PAR38 [PAR 4.75 inch/121mm]
Approval and application	
Suitable For Accent Lighting	Yes
Energy Consumption kWh/1000 h	- kWh
Product data	
Order product name	13.5PAR38/PER/BLUE/ND/ULW/G/120V 4/1FB
EAN/UPC - Product	046677469078
Order code	469072
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	4

Party Spot

Material Nr. (12NC)	929001306513
Net Weight (Piece)	0.849 lb


Dimensional drawing

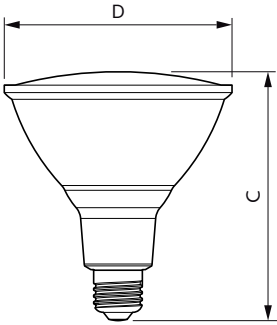


13.5PAR38/PER/BLUE/ND/ULW/G/120V 4/1FB

Product	D	C
13.5PAR38/PER/BLUE/ND/ULW/G/120V 4/1FB	4-13/16 in	5-1/4 in

Photometric data

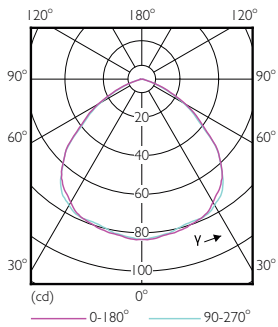


LEDspots 13,5W E26 PAR38 Blue

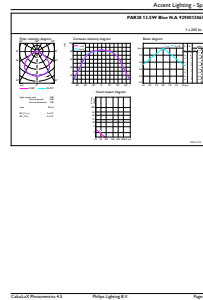


LEDspots 13,5W E26 PAR38 Blue

Lifetime

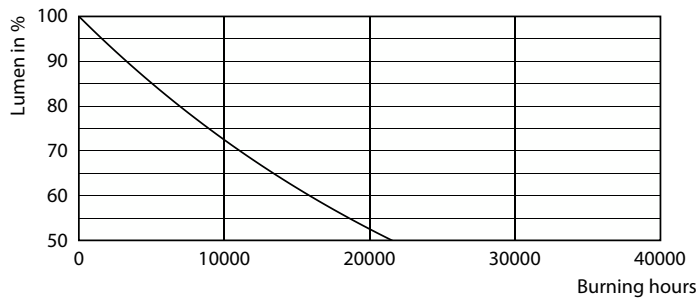

Lumen Maintenance Diagram

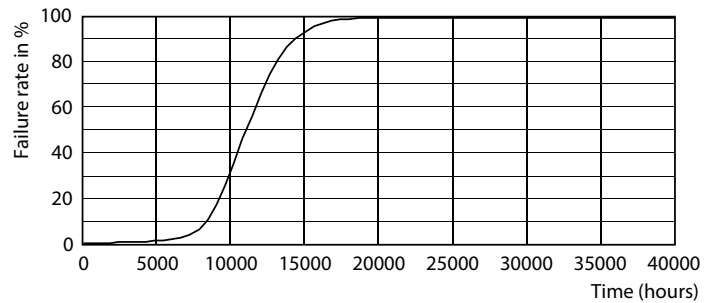

Life Expectancy Diagram

Party Spot

