



A-Shape LED

8.8A19/LED/927/FR/P/E26/ND/T20 6/1FB

Philips A-shape LED lamps are the LED alternative to standard incandescents. It provides beautiful light and dependable performance you expect from LED at an affordable price.

Product data


General information	
Base	E26 [Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	11000 h
Switching Cycle	50000
Tier	CorePro
Light technical	
Color Code	927 [CCT of 2700K]
Beam Angle (Nom)	250 °
Initial lumen (Nom)	800 lm
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	2700 K
Luminous Efficacy (rated) (Nom)	90.00 lm/W
Color Consistency	<4
Color Rendering Index (Nom)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	8.8 W
Lamp Current (Nom)	76 mA
Wattage Equivalent	60 W
Starting Time (Nom)	0.5 s

Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.7
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	185 °F
Controls and dimming	
Dimmable	No
Mechanical and housing	
Bulb Finish	Frosted
Bulb Material	Plastic
Bulb Shape	A19 (A19)
Approval and application	
Energy Certifications	No
Product data	
Order product name	8.8A19/LED/927/FR/P/E26/ND/T20 6/1FB
EAN/UPC - Product	046677571610
Order code	571612
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6

A-Shape LED

Material Nr. (12NC)	929003020204
Net Weight (Piece)	0.066 lb


Dimensional drawing

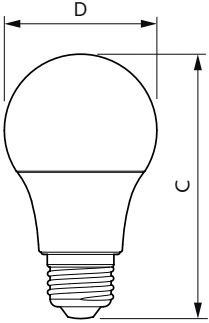


8.8A19/LED/927/FR/P/E26/ND/T20 6/1FB

Product	D	C
8.8A19/LED/927/FR/P/E26/ND/T20 6/1FB	2-3/8 in	4-1/8 in


Photometric data

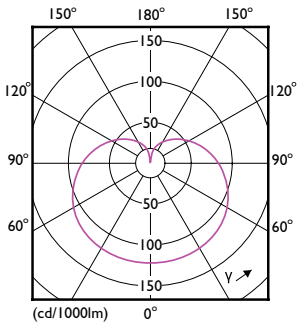

LEDbulb T20 A19 8,8W E26 927 FR-LDD

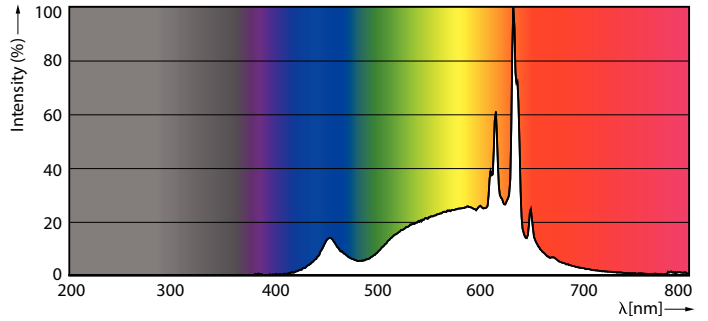



LEDbulb T20 8,8W A19 E26 927 FR-POC

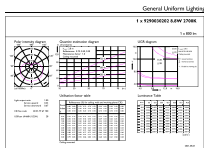

LEDbulb T20 8,8W A19 E26 927 FR 1-GUL

A-Shape LED

Lifetime

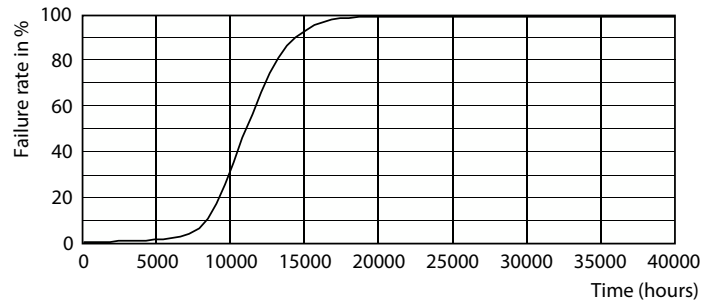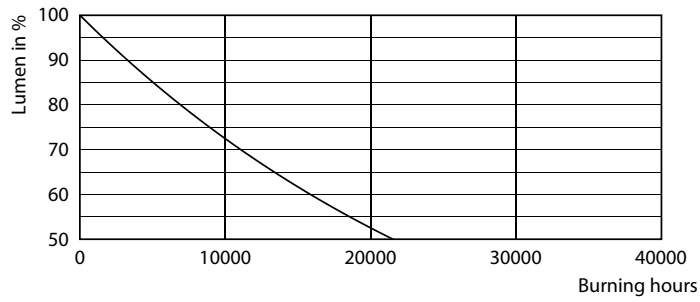

Lumen Maintenance Diagram

Life Expectancy Diagram

