



LED Small Spots

4GU10/LED/927-22/F35/G/WG/T20 10/1

Philips standard and Glass LED spots are a perfect fit for basic spot lighting and deliver warm halogen-like light. They are compatible with most existing fixtures with a GU10 socket and are designed as a retrofit replacement for halogen spots. They provide the beautiful light and performance you expect from the LED technology at an affordable price.

Product data

General information	
Base	GU10 [GU10]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	25000 h
Switching Cycle	50000
Tier	MasterClass
Light technical	
Color Code	927-922 [CCT of 2700K-2200K]
Beam Angle (Nom)	35 °
Initial lumen (Nom)	380 lm
Luminous Intensity (Nom)	600 cd
Color Designation	Warm Glow(WG)
Correlated Color Temperature (Nom)	2200 2700 K
Luminous Efficacy (rated) (Nom)	95.00 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and electrical	
Input Frequency	50 to 60 Hz
Power (Rated) (Nom)	4 W


Lamp Current (Nom)	50 mA
Wattage Equivalent	50 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.7
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	149 °F
Controls and dimming	
Dimmable	Yes
Mechanical and housing	
Bulb Finish	Clear
Bulb Material	Glass
Bulb Shape	MR16 [2inch/50mm]
Approval and application	
Suitable For Accent Lighting	Yes
Energy Consumption kWh/1000 h	- kWh

LED Small Spots

Energy Certifications	Energy Star
Product data	
Order product name	4GU10/LED/927-22/F35/G/WG/T20 10/1
EAN/UPC - Product	046677471569
Order code	471565

Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929002055304
Net Weight (Piece)	0.132 lb


Dimensional drawing

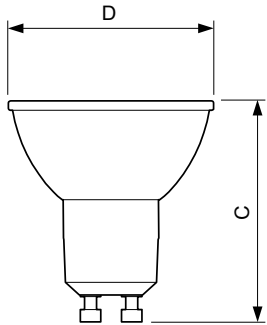


4GU10/LED/927-22/F35/G/WG/T20 10/1

Product	D	C
4GU10/LED/927-22/F35/G/WG/T20 10/1	2 in	2-1/8 in


Photometric data

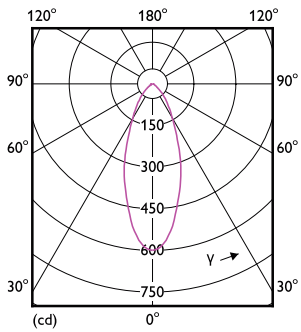

LEDspot T20 GU10

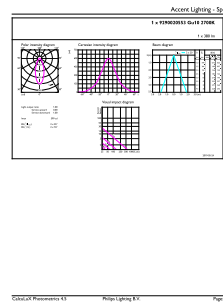



LEDspot T20 GU10 2700

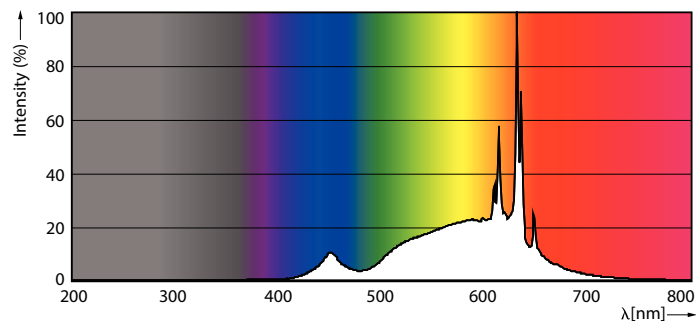

LEDspot T20 GU10 2700

LED Small Spots

Lifetime

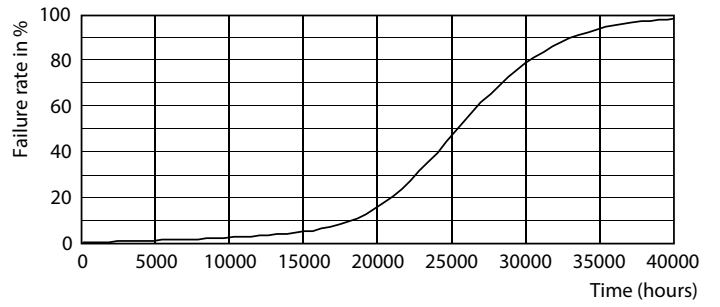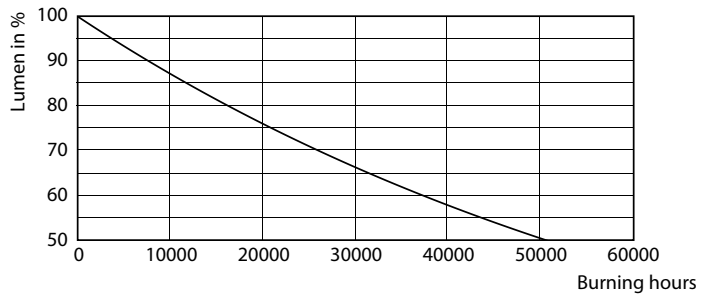

LEDSpot T20 GU10

LEDSpot T20 GU10

