



# TrueForce High Lumen PAR

## 33PAR38/PER/830/F25/DIM/120V B 6/1FB

Philips LED TrueForce PAR high lumen lamps are the perfect transition from CDM lamps to LED.

### Product data

General information	
Base	E26 [ Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	25000 h
Switching Cycle	50000
Tier	MasterClass

Light technical	
Color Code	830 [ CCT of 3000K]
Beam Angle (Nom)	25 °
Initial lumen (Nom)	3000 lm
Luminous Intensity (Nom)	10000 cd
Color Designation	White (WH)
Correlated Color Temperature (Nom)	3000 K
Luminous Efficacy (rated) (Nom)	90.00 lm/W
Color Consistency	<4
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %

Operating and electrical	
Input Frequency	50 to 60 Hz
Power (Rated) (Nom)	33 W

Lamp Current (Nom)	300 mA
Wattage Equivalent	250 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.95
Voltage (Nom)	120 V

Temperature	
T-Case Maximum (Nom)	194 °F

Controls and dimming	
Dimmable	Yes

Mechanical and housing	
Bulb Finish	Clear
Bulb Material	Aluminum
Bulb Shape	PAR38 [ PAR 4.75 inch/121mm]


Approval and application	
Suitable For Accent Lighting	Yes
Energy Consumption kWh/1000 h	- kWh

# TrueForce High Lumen PAR

Energy Certifications	Energy Star
<b>Product data</b>	
Order product name	33PAR38/PER/830/F25/DIM/120V B 6/1FB
EAN/UPC - Product	046677534639
Order code	534636

Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	929001919704
Net Weight (Piece)	0.948 lb


## Dimensional drawing

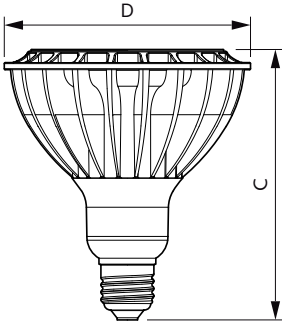


33PAR38/PER/830/F25/DIM/120V B 6/1FB

Product	D	C
33PAR38/PER/830/F25/DIM/120V B 6/1FB	4-7/8 in	5-1/4 in


## Photometric data

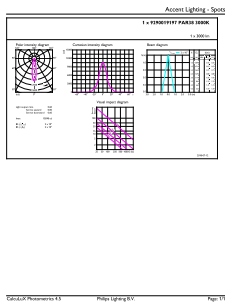

LEDSpot 33W E26 PAR38 F25 B

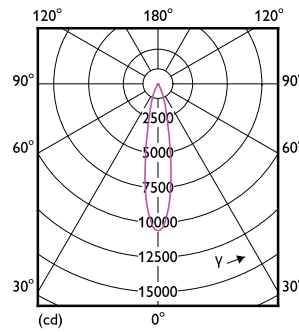


LEDSpot 33W E26 PAR38 F25

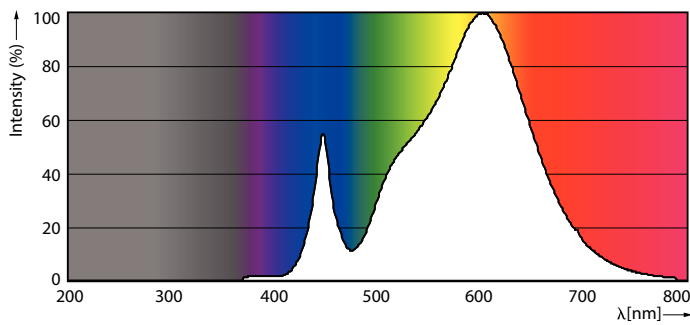


LEDSpot 33W E26 PAR38

# TrueForce High Lumen PAR

## Lifetime

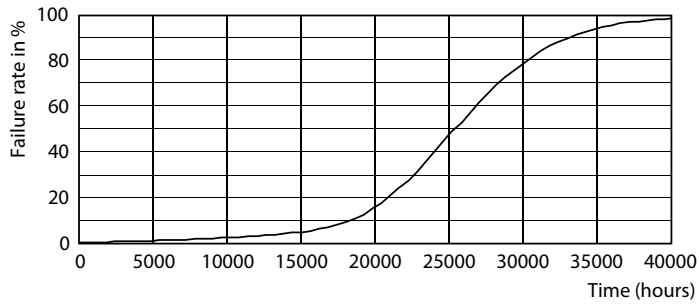

LEDSpot 33W E26 PAR38

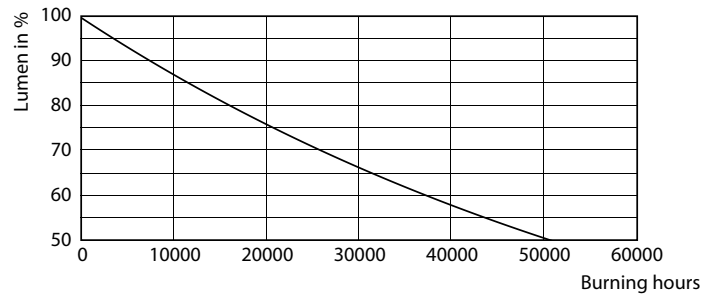

LEDSpot 33W E26 PAR38

