

DATE:	LOCATION:
TYPE:	PROJECT:
CATALOG #:	

tradeSELECT®

FEATURES

- LED life-cycle of more than 10 years
- Quick installation
- Dual-voltage 120 or 277V AC input
- Remote capacity or extended runtime option
- Damp Location Listed 20°C to 30°C (68°F to 86°F)
- Fully adjustable, glare-free, lamp-heads
- Provided with test switch and AC-On indicator
- Wall or Ceiling mount



SPECIFICATIONS

DESCRIPTION

- The CU2 Series offers quality and value with a compact and attractive LED based emergency light
- The white or black housing and lamp-heads are made of high impact UL flame rated thermoplastic
- Snap together design for quick and easy installation with option of Wall or Ceiling mount
- Remote capacity unit will run a double-head remote or 2 single-head remotes of either the Compass CIR or COR Series

DESCRIPTION

- Also available with self-test/self-diagnostics to monitor battery/charger failure, battery disconnect and lamp failure
- Includes long-life Nickel Cadmium (NiCad) or Nickel Metal Hydride (NiMh) battery for UL recognized 90 minute emergency lighting
- Remote Capacity(RC) models have a minimum runtime of 120 minutes when no remotes are installed

COMPLIANCES

- UL924 Listed for Damp Location
- NFPA 101 and NFPA 70
- OSHA
- CEC T20 Compliance

WARRANTY

- 2 year full unit warranty

APPLICATION

- The CC SQ series can be applied in stair-wells, hallways, offices and commercial applications

ORDERING GUIDE


Catalog Number	Description	Accessories (Order Separately)
CU2	White Finish, Dual-Head LED Emergency Light , 120/277 Input, NiCad Battery, 3 VDC, 1Watt, CEC T20 Compliant	WGEL Wireguard 6.25"H x 14"W x 4" D
CU2B	Black Finish, Dual-Head LED Emergency Light, 120/277 Input, NiCad Battery, 3 VDC, 1 Watt, CEC T20 Compliant	
CU2RC	White Finish, Dual-Head LED Emergency Light, 120/277 Input, NiMh Battery, Remote Capacity, 3VDC, 1Watt	CIR Series Matching LED Indoor Remote Heads
CU2RCB	Black Finish, Dual-Head LED Emergency Light, 120/277 Input, NiMh Battery, Remote Capacity, 3VDC, 1Watt	
CU2SD	White Finish, Dual-Head LED Emergency Light, 120/277VAC, NiCad Batt., 3 VDC, 1Watt, Self-Test/Self-Diagnostics, CEC T20 Compliant	COR Series Matching LED Outdoor Remote Heads
CU2RCSD	White Finish, Dual-Head LED Emergency Light, 120/277VAC, NiMh Batt. Remote Capacity, 3VDC, 1Watt, Self-Test/Self-Diagnostics	

Note: Remote Capacity Unit will only power the Compass Indoor and Outdoor Remote (CIR and COR Series)

ENERGY CONSUMPTION


	120 VAC	277 VAC
CU2	.56W	.54W
CU2RC	.92W	1.62W

DIMENSIONS

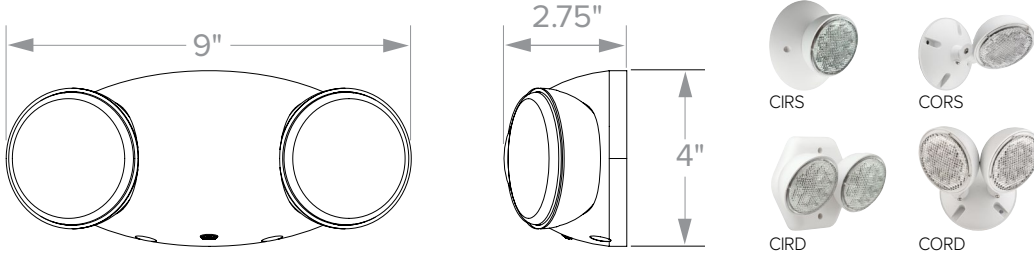

Single Carton Weight	1 lbs.
Master Carton Quantity	12 each

APPLICATION INFORMATION

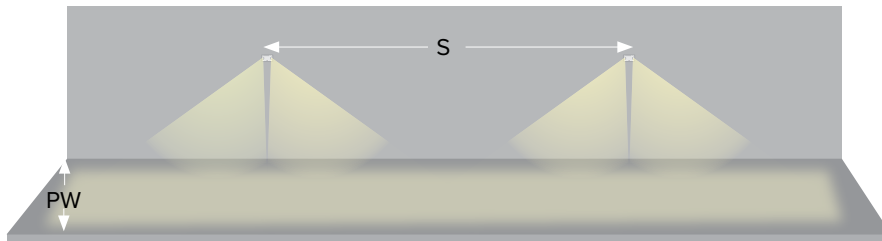

1 fc Average	
Path Width (PW)	Spacing (S)
6'	16'

Note: Meets Life Safety Code minimum illuminance of 0.1 fc and average illuminance of 1.0 fc. Assumes open space with no obstructions, ceiling height of 9' and reflectances of 80/50/20. Photometry files available on the website.