


DATE:	LOCATION:
TYPE:	PROJECT:
CATALOG #:	

tradeSELECT®

FEATURES

- Switchable Lumen technology:
2800/3200/4100 lumens (2x2 size)
4200/5200/6000 lumens (2x4 size)
- Switchable CCT technology: 3500/4000/5000K
- 80+ CRI
- 0–10V dimming, standard
- Universal voltage (120–277V)
- 2,750 to 7,000 nominal lumens
- Up to 140 lumens per watt
- 5-Wire flex and EM battery pack available

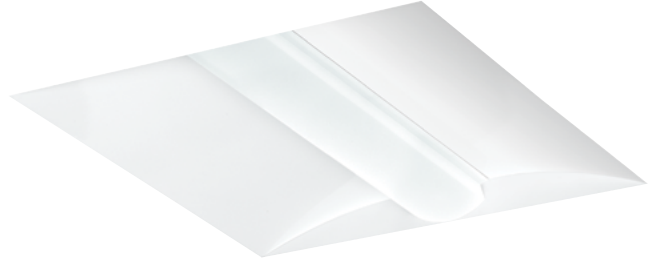

See Certification Specifications

SPECIFICATIONS

OPTICS

- Frosted acrylic lens

INSTALLATION

- Fully assembled for quick installation

ELECTRICAL

- 54,000 hour LEDs at L70 for reduced maintenance

CERTIFICATIONS

- All luminaires are built to UL 1598 standards and bear appropriate CSA labels
- Damp location label standard
- Emergency-equipped fixtures labeled UL 924 unless specified
- IC rated
- This product qualifies as a “designated country construction material” per FAR 52.225-11 Buy American-Construction Materials under Trade Agreements effective 09/01/2021.

CERTIFICATIONS (CONTINUED)

- DLC® (DesignLights Consortium) Qualified. Please refer to the DLC website for specific product qualifications at www.designlights.org

WARRANTY

- 5 year warranty

ORDERING GUIDE

Catalog No.	UPC	Description	Setting	Lumens			Watts	LPW		
				3500K	4000K	5000K		3500K	4000K	5000K
<input type="checkbox"/> CCL22-LSCS	840141422664	2X2 Center Lens LED Troffer, Lumen Switchable, CCT Switchable	LOW	2642	2929	2872	21	126	139	137
			MED	3008	3387	3272	25	120	135	131
			HIGH	3764	4460	4124	35	108	127	118
<input type="checkbox"/> CCL24-LSCS	840141422671	2X4 Center Lens LED Troffer, Lumen Switchable, CCT Switchable	LOW	3964	4424	4285	32	126	140	136
			MED	4872	5608	5282	42	116	134	126
			HIGH	5415	6394	5874	51	106	125	115

-ELL14 (Emergency Battery Pack Installed, 1400 Lumens) or -C588 (5-wire Flex) options are available for order

Accessories (Order Separately)		
FK22	2' x 2'	Single Flange Kit (Shipped separately)
FK24	2' x 4'	Single Flange Kit (Shipped separately)

KEY DATA	
Lumen Range	2642–6394
Wattage Range	21–51
Efficacy Range (LPW)	108–140
Reported Life (Hours)	L70/54,000

DIMENSIONS

