

Type ANE Automotive / Marine Limiter Fast Acting



www.optifuse.com (619) 593-5050

Specifications:

- **Voltage Rating:** 125 VAC, 32 VDC
- **Amperage Rating:** 35A, 40A, 50A, 60A, 70A, 80A, 100A, 120A, 125A, 130A, 150A, 175A, 200A, 225A, 250A, 275A, 300A, 350A, 400A


- **Construction:**
Body Material: FR4
Terminals: Gold-plated Brass/Copper Alloy

Time Characteristics	
% of Rated Current	Clearing Time
100%	Min 4h
250%	Max 300s

Recommended Mounting:

- Optifuse Fuse Block BLC-09 to 200A
- Optifuse Fuse Block BLC-209 to 800A

Mechanical Dimensions: Inches [mm]

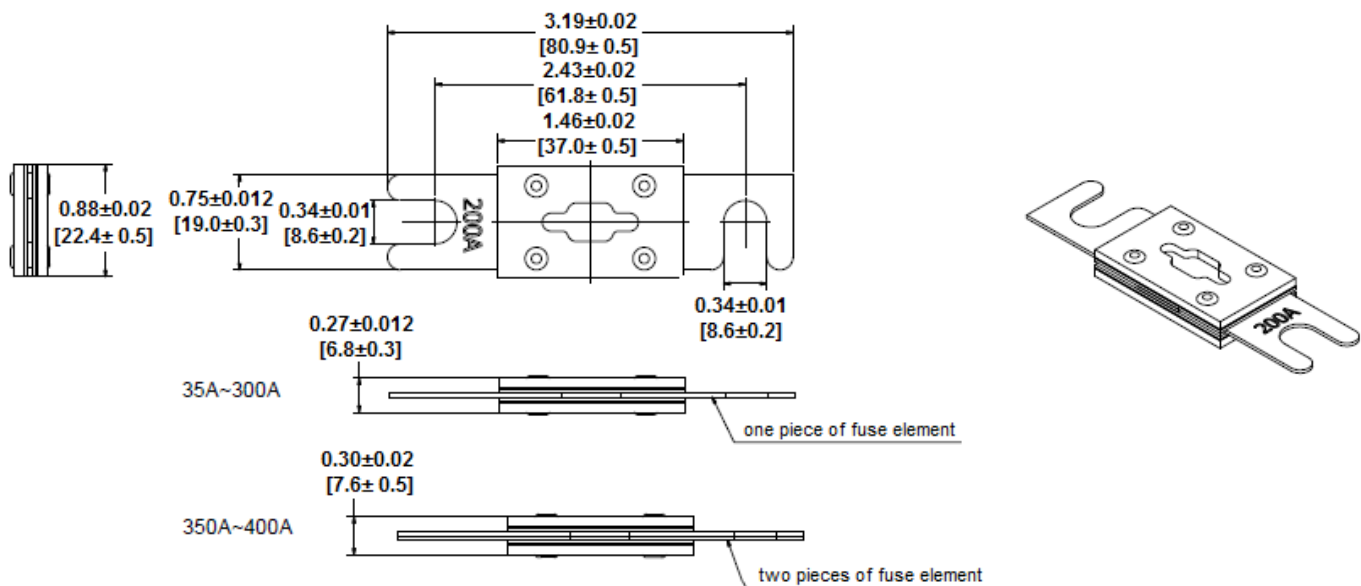

Warning:



- Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame.
- Avoid contact of device with chemical solvent. Prolonged contact may damage the device performance.

**Type ANE
Automotive / Marine Limiter
Fast Acting**



www.optifuse.com

(619) 593-5050

TIME CURRENT CURVE GRAPH

