

# Type FSO

## Fast Acting Glass Tube Fuse

### Automotive Fuse



www.optifuse.com

(800) 621-0326

**Product Size:** Ø6.3x25.4mm (Ø1/4"x1")


**Ampere Rating:** 4A~30A

**Voltage Rating:** 32VDC and less

**Agency Standards and Listings:**



**Mechanical Dimensions: Inches[mm]**

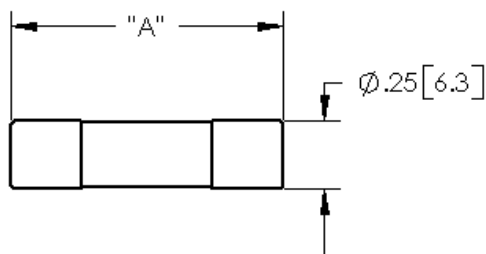

Catalog Number	"A" Length	"A" Length
	Inches	MM
FSO-4A	5/8	15.9
FSO-6A	3/4	19.0
FSO-7.5A	7/8	22.2
FSO-9A	7/8	22.2
FSO-14A	1-1/16	27.0
FSO-20A	1-1/4	31.7
FSO-30A	1-7/16	36.5

#### General Info:

For Automotive Circuits


Visual indication glass body

SAE specifications

Size varies with rating to prevent over-fusing

For use with In-Line holders and 1/4" clips.

Time-Current Characteristics--Total Clear

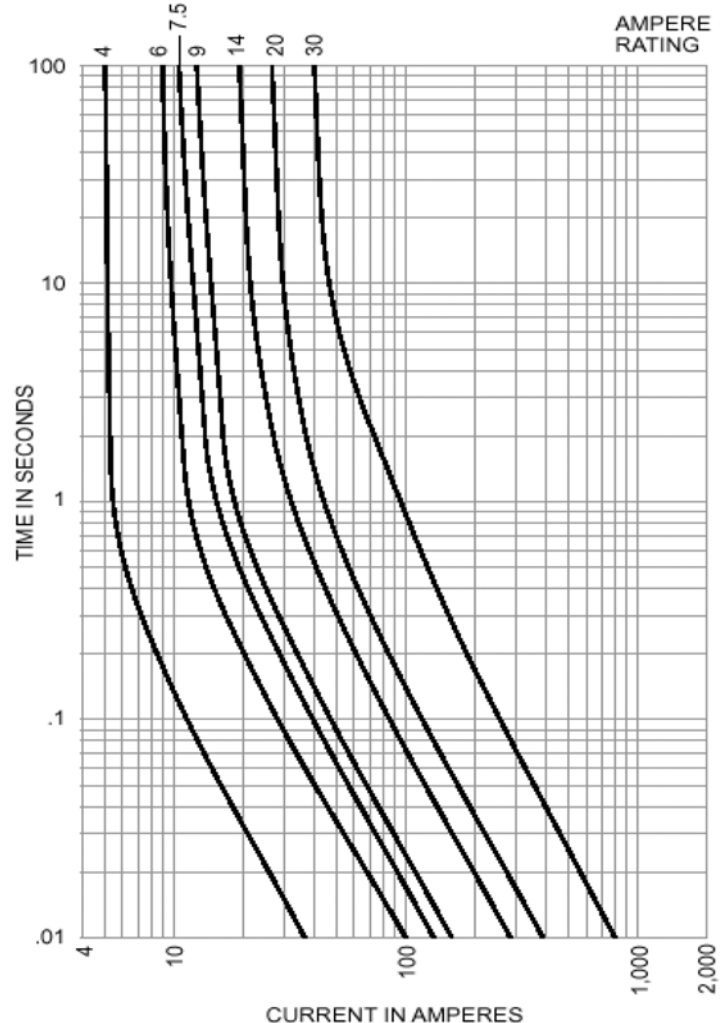

#### Warning:



- Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame.
- Glass Tube device are intended for occasional overcurrent protection. Application for repeated overcurrent condition and/or prolonged trip are not anticipated.
- Avoid contact of Glass Tube device with chemical solvent. Prolonged contact will damage the device performance.

Note: All specifications subject to change without notice.

Rev B 08/2006 - Page: 1/1  
Code: C01