

Type APG Auto Glass Fuse Links European Style



www.optifuse.com (619) 593-5050


Specifications:

- Voltage: 32V DC
- Amperage: 5A, 8A, 16A, 25A, 30A
- Body: Bakelite
- Terminals: Spring Brass

Part Number	Amperage	Body Color
APG-5A	5A	Yellow
APG-8A	8A	White
APG-16A	16A	Red
APG-25A	25A	Blue
APG-30A	30A	Green

Time Characteristics:	
% of Rated Current	Max Hold Time
150%	<=1h
250%	<=1m

Mechanical Dimensions: Inches [mm]

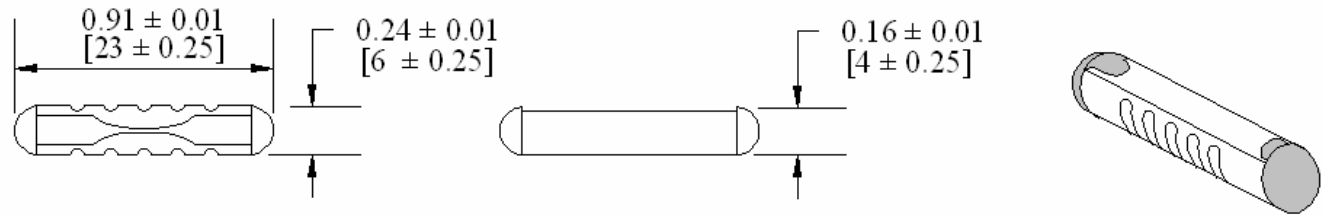

Warning:



- Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame.
- Avoid contact of device with chemical solvent. Prolonged contact may damage the device performance.