

# Type ACB2-PL

## Auto Reset Circuit Breaker

### Automotive Type I

### Plug-In Type



www.optifuse.com

(619) 593-5050


#### Specifications:

- Auto Reset Type Circuit Breaker
- Voltage: Up to 12V
- Amperage: 10A, 15A, 20A, 25A, 30A, 35A, 40A
- Material: Zinc plated Metal Cover
- Conforms to American National Standard SAE J553
- Operating Temperature: -10° F ~ 150° F
- Storage Temperature: -20° F ~ 200° F

#### Current Rating:

Rating	Open Time
100% ± 1.5%	> 30 Min
135% ± 1.5%	< 30 Min
200% ± 1.5%	< 1 Min

#### Mechanical Dimensions: Inches [mm]

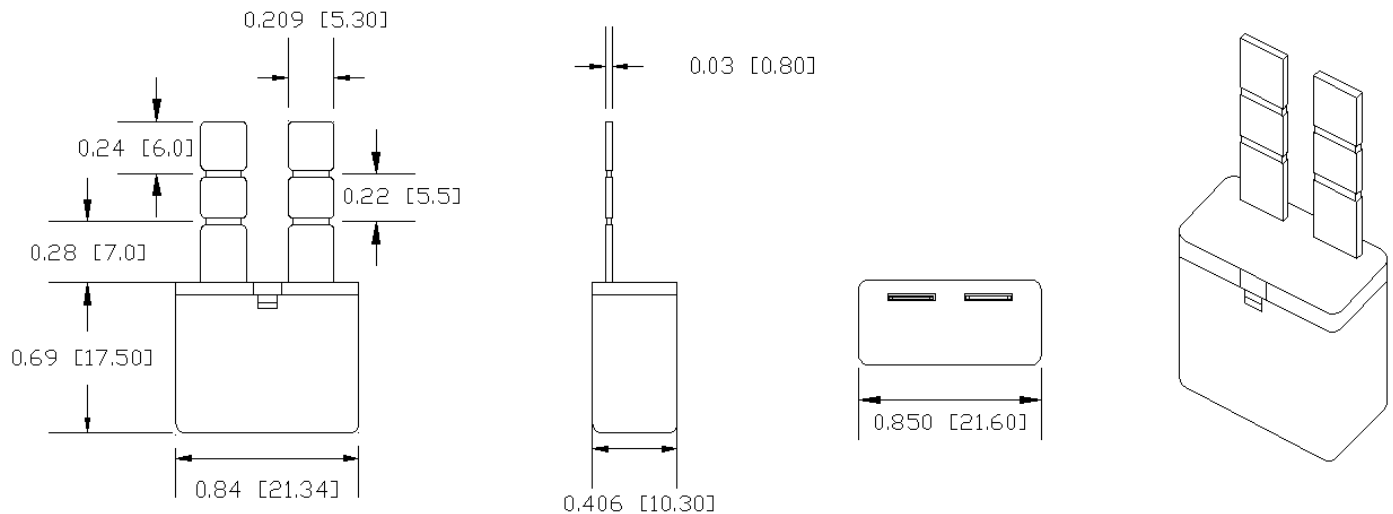

#### Warning:



- Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame.
- Device are intended for occasional overcurrent protection. Application for repeated overcurrent condition and/or prolonged trip are not anticipated.
- Avoid contact of device with chemical solvent. Prolonged contact may damage the device performance.