

Type FSW

Fast Acting Glass Tube Fuse

Automotive Glass



www.optifuse.com (619) 593-5050

Fuse Size: 1/4" x 7/8" (6.3 x 22.2mm)


Ampere Rating: 100mA ~ 30A

Voltage Rating: 125V / 32V

Electrical Characteristics:

| | | |
|------|------|------|
| 100% | 135% | 200% |
| Min. | Max. | Max. |
| 4h | 1h | 120s |

Mechanical Dimensions: Inches[mm]

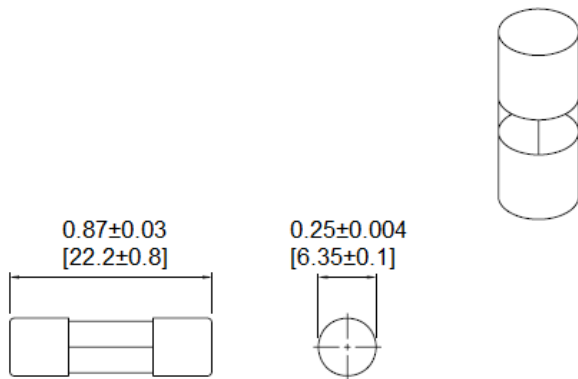

| Part Number | Ampere Rating | Interrupt Rating | Voltage Rating |
|-------------|---------------|------------------|----------------|
| FSW-100mA | 100mA | 10KA @125VAC | 125V |
| FSW-125mA | 125mA | | |
| FSW-160mA | 160mA | | |
| FSW-200mA | 200mA | | |
| FSW-250mA | 250mA | | |
| FSW-300mA | 300mA | | |
| FSW-315mA | 315mA | | |
| FSW-400mA | 400mA | | |
| FSW-500mA | 500mA | | |
| FSW-600mA | 600mA | | |
| FSW-630mA | 630mA | | |
| FSW-700mA | 700mA | | |
| FSW-800mA | 800mA | | |
| FSW-1A | 1A | | |
| FSW-1.25A | 1.25A | | |
| FSW-1.5A | 1.5A | | |
| FSW-1.6A | 1.6A | | |
| FSW-2A | 2A | 200A @125VAC | 125V |
| FSW-2.5A | 2.5A | | |
| FSW-3A | 3A | | |
| FSW-3.15A | 3.15A | | |
| FSW-3.5A | 3.5A | | |
| FSW-4A | 4A | | |
| FSW-5A | 5A | 1000A @32VAC,VDC | 32V |
| FSW-6A | 6A | | |
| FSW-6.3A | 6.3A | | |
| FSW-7A | 7A | | |
| FSW-8A | 8A | | |
| FSW-10A | 10A | | |
| FSW-12A | 12A | | |
| FSW-13A | 13A | | |
| FSW-15A | 15A | | |
| FSW-16A | 16A | | |
| FSW-20A | 20A | | |
| FSW-25A | 25A | | |
| FSW-30A | 30A | | |

| | |
|------------------------|---|
| <p>Warning:</p> | -Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame. |
| | -Avoid contact of Fuse device with chemical solvent. Prolonged contact may damage the device performance. |