

# Type LPX-23

## In-Line Fuse Holder

### Maxi Automotive Blade Fuses

### Splashproof Cap



www.optifuse.com

(619) 593-5050

#### Ratings:

**Fuse Type:** Maxi Automotive Blade – ANX / APX

**Amperage:** Rated for current up to 80A

**Voltage:** Max 80VDC

**Body:** PVC

**Contacts:** Brass

**Cap:** Splashproof Cap

**IP Rating:** IP65

**Standard Wire Size:** #8 AWG

**Standard Wire Color:** Red

**Standard Body Color:** Black

**Standard Wire Length:** 12 inch Loop


#### Part number format

**LPX-23B-8R-Loop**



Available in various wire gauges and lengths, and body and wire colors.  
Contact factory for those not listed above.

#### Mechanical Dimensions: Inches [mm]

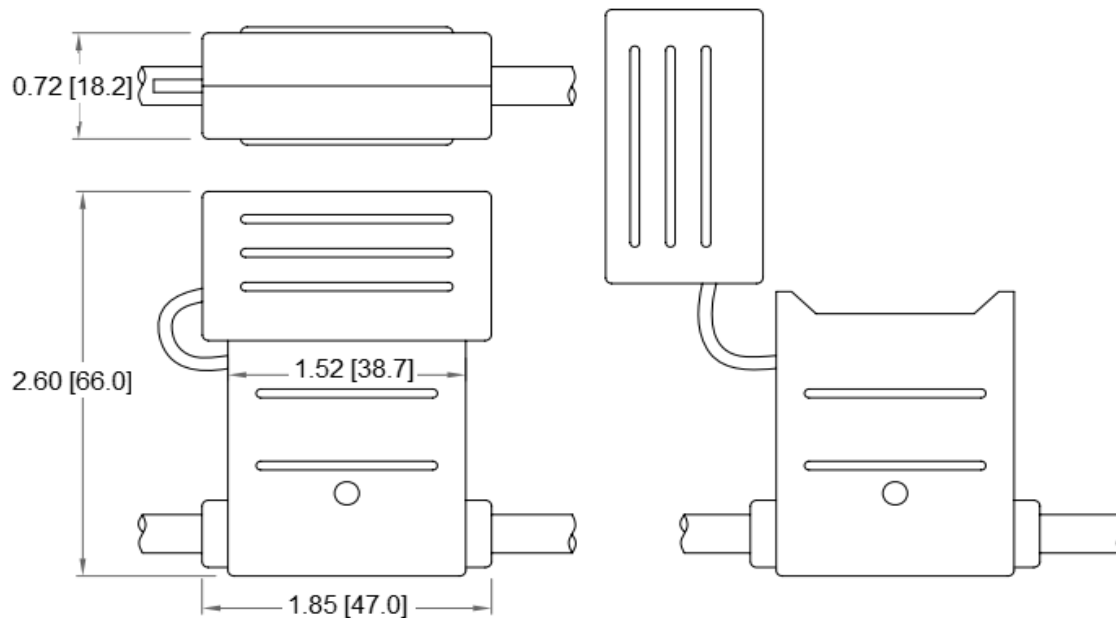

#### Warning:



- Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame.
- Avoid contact of device with chemical solvent. Prolonged contact may damage the device performance.
- Not designed for prolonged liquid exposure or submersible applications.