


BLK,PVC,4X26 General Purpose Cable – Reelfast™ Bulk Cable



Features

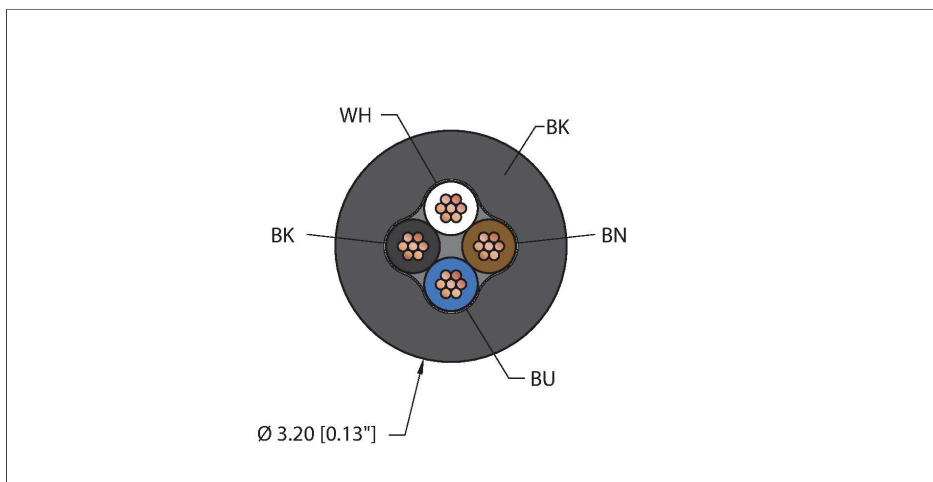

- General Purpose Cable
- Black PVC jacket, 4X26 AWG
- -40 Cold Bend Rating
- 300V

Technical data

Type	BLK,PVC,4X26
ID	RF50590
Cable data	
Cable Platform	General Purpose Cable
Total number of conductors	4
Cable diameter	Ø 3.2 mm
Cable jacket	PVC, Black
Conductor diameter	0.039 "
Conductor material	TC (tinned copper)
Conductor insulation material	PVC
Conductor size	4 x 26 AWG [Similar to 0.14 mm ²]
Number of strands x O.D.	7 x 34 AWG
Conductor colors	WH, BN, BU, BK
Weight	0.035 lbs. /meter
Electrical properties at +20 °C	
Voltage	300V
Dielectric withstand (min.)	2 KVAC
DC resistance (max)	40.8 Ω/1000ft max
Mechanical and chemical properties	
Bending radius (static)	≥ 5 x Ø
Bending radius (dynamic)	≥ 10 x Ø
UL cold bend rating	-40 °C
Ambient temperature range (static)	-40 °C...+105 °C

Technical data

Ambient temperature range (dynamic)	-40 °C...+105 °C
-------------------------------------	------------------

Temperature range (installation)	-20 °C...+105 °C
----------------------------------	------------------

Approval

Compliances	RoHS
-------------	------

Note

- Flex ratings may be reduced if used in extreme temperatures, exposure to certain chemicals, operating above the rated cycle speed, or operating below the rated cable bend radius.

- We reserve the right to make technical alterations without prior notice.