


## Coaxial PCB Connector 82\_MCX-S75-0-2/111\_N

### Description

Straight PCB jack

Interface Standards

IEC 60169-36\_CECC 22220

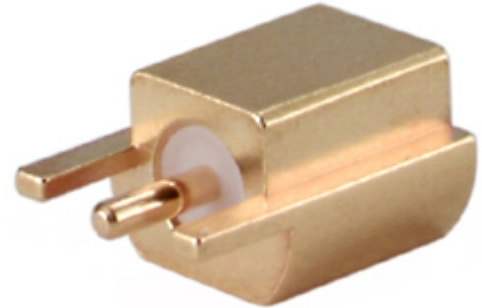

### Technical Data

#### Electrical Data

Impedance	75 Ω
Interface frequency max.	6 GHz

#### Mechanical Data

Board mounting type	edge mount
Weight	0.0009 kg

#### Environmental Data

Operating temperature	-65 °C to 165 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

#### Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium Alloy	SUCOPRO Plating
Outer contact	Brass	SUCOPRO Plating
Body	Brass	SUCOPRO Plating
Insulator	PFA / PTFE	

### Related Documents

Outline drawing	DOU-00013375
Catalogue drawing	DCA-00013377

### Ordering Information

Single package	82_MCX-S75-0-2/111_NE
Bulk 100 pcs package	82_MCX-S75-0-2/111_NH

### Remarks

PCB connector without stand-offs