


PX0108S03GY Datasheet

Product Name // 3 Contacts Male Standard Rectangular Grey Connector - SBA

[View Product Page](#)

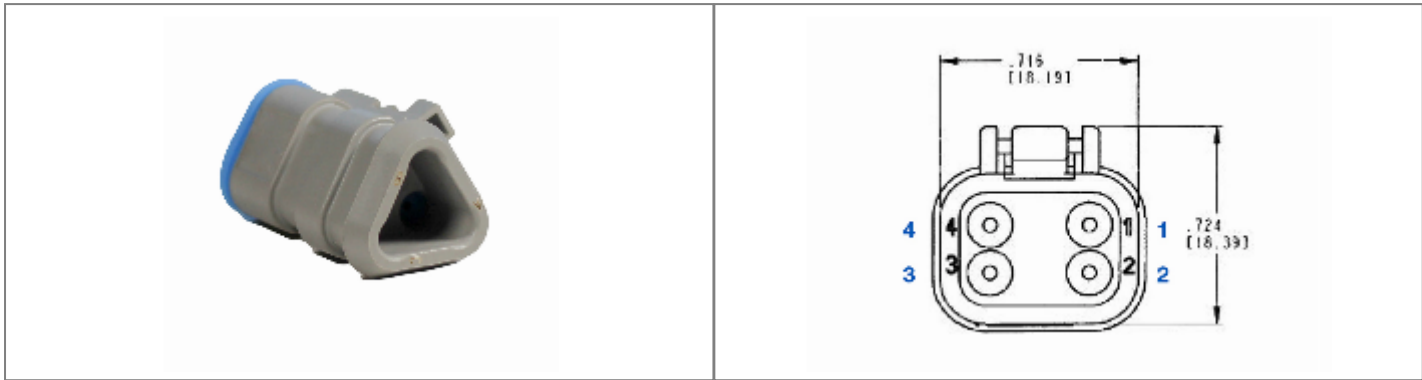

// Product Description:

- ⊞ 3 Contacts Male Standard Rectangular Grey Connector - SBA
- ⊞ Shrink Boot Adapter (SBA) Included
- ⊞ IP68 rated when mated
- ⊞ Mate with PX0109 Series
- ⊞ Wedge locks provided
- ⊞ Crimp Terminals
- ⊞ Mechanical Cycles=100 (min)
- ⊞ Operating Temperature= -55Â°C to +125Â°C

// General Information:

Product Display Title:	3 Contacts Male Standard Rectangular Grey Connector - SBA
Product Family:	Rectangular Connectors
Product Series:	Standard Rectangular Connectors
Body Colour:	Grey
Body Material:	Polycarbonate/Polybutylene Terephthalate (PC/PBT)
Body Material Type:	Plastic Body
Contact Type:	Socket Contact
Coupling Type:	Snap-in
Current Max:	13A
Dielectric Withstanding Voltage:	1500V
Durability:	>100 Cycles
Function:	Straight Male Connector
Insulation Resistance:	>1000MOhms
Ip Rating:	IP68
Max Contact Accomodation Awg:	20AWG
Min Contact Accomodation Awg:	14AWG
Max Operating Temperature:	+125°C
Min Operating Temperature:	-55°C
Number Of Contacts:	3 Contacts
Rohs Compliant:	Yes
Voltage Max:	250V

// Product PDF Links

[Rectangular Power Connector...](#)