

24

2431

USB and IEEE 1394 connectors




USB 2.0 connecting cable, type A plug to type B plug

State: Obsolete


24

2431

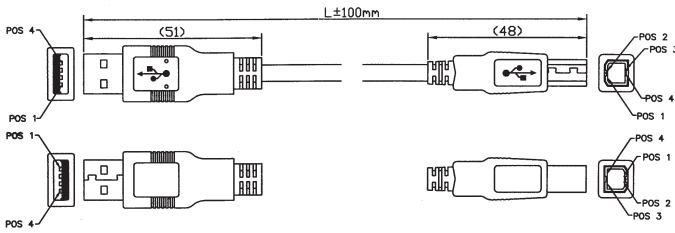

2431 01	UL2725 AWG28 x 1P + AWG24 x 2C + Al-Foil + Drain + Braid
2431 02	UL2725 AWG28 x 1P + AWG24 x 2C + Al-Foil + Drain + Braid
2431 03	UL2725 AWG28 x 1P + AWG24 x 2C + Al-Foil + Drain + Braid
2431 05	UL2725 AWG28 x 1P + AWG20 x 2C + Al-Foil + Drain + Braid

USB PLUG (SERIES A)		USB PLUG (SERIES B)	
1	RED (Vbus)	1	
2	WHITE (Data-)	2	
3	GREEN (Data+)	3	
4	BLACK (GRND)	4	
SHELL	OVERALL SHIELD	SHELL	

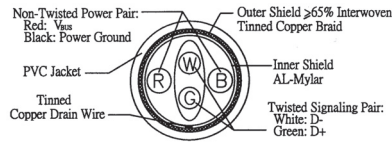

Materials

Overmolding/handle PVC

Connected cable

Construction USB 2.0 high/full speed
UL2725 28 AWG x 1P + 20 AWG x 2C + Al-foil + drain + braid

Electrical data (at T_{amb} 20 °C)

Rated current 1 A
Rated voltage 30 V AC

Associated products

Counterparts

1673 01	2410 01	2410 02
2410 03	2410 05	2410 06
2410 09	2410 10	2410 11
2410 12	2410 13	2410 14
2411 01	2411 02	2411 03
2411 04	2411 05	2411 06
2411 07	2420 01	2483 01
4512		

24

2431

Designation	Pole Number	PU (Pieces)	MDQ (Pieces)	Dimensions L (mm)
2431 01	4	100	200	1000
2431 02	4	100	200	2000
2431 03	4	50	200	3000
2431 05	4	50	200	5000

Packaging:

in bulk, in a cardboard box or a plastic bag