

Han USB 3.0 module

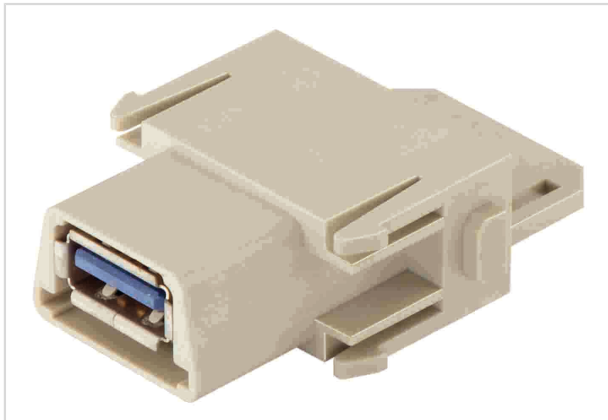


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 001 4703
Specification	Han USB 3.0 module
HARTING eCatalogue	https://b2b.harting.com/09140014703

Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® USB module
Description of the module	for patch cable

Version

Gender	Female
Number of contacts	8
Details	USB 3.0

Technical characteristics

Rated current	1 A
Rated voltage	50 V
Rated impulse voltage	0.8 kV
Pollution degree	3
Rated voltage acc. to UL	30 V
Insulation resistance	$>10^{10} \Omega$
Limiting temperature	-40 ... +85 °C
Mating cycles	≥ 500

Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)



Pushing Performance

Material properties

Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No

Specifications and approvals

Specifications	EN 60664-1 IEC 60352-4
Approvals	DNV GL

Commercial data

Packaging size	1
Net weight	14.22 g
Country of origin	Germany
European customs tariff number	85366990
eCl@ss	27440218 Module for industrial connectors (data)