

## RJ45 Kabel AWG 22/1;2xIP20;50m,mass.;;Over

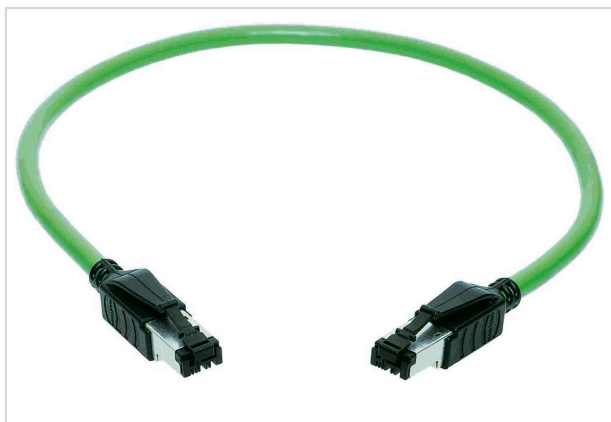


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 771 0056
Specification	RJ45 Kabel AWG 22/1;2xIP20;50m,mass.;;Over
HARTING eCatalogue	<a href="https://b2b.harting.com/09457710056">https://b2b.harting.com/09457710056</a>

### Identification

Category	System cabling
Series	RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	HARTING RJ Industrial®
Connector 2	HARTING RJ Industrial®
Type of cable	Copper cable (round)
Description of the cable	Straight

### Version

Cable length	50 m
Number of cores	4
Core structure	4x AWG 22/1

### Technical characteristics

Transmission characteristics	Cat. 5 Class D up to 100 MHz
Data rate	10 Mbit/s 100 Mbit/s

### Material properties

Material (cable)	PVC
Colour (cable)	Green
RoHS	compliant



**Pushing Performance**  
Since 1945

## Material properties

ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Nickel

## Commercial data

Packaging size	1
Net weight	3,659 g
Country of origin	Romania
European customs tariff number	85444290
GTIN	5713140063921
eCl@ss	27060308 Patch cord copper (data cable)