

## Han B Protect Cover Die Cast f Hood PG16

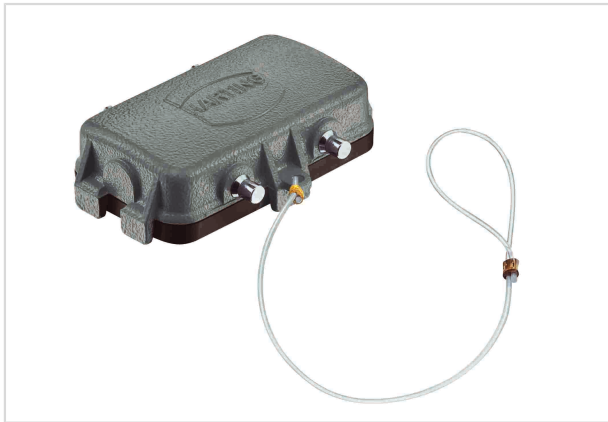


Image is for illustration purposes only. Please refer to product description.

Part number	09 30 010 5457
Specification	Han B Protect Cover Die Cast f Hood PG16
HARTING eCatalogue	<a href="https://b2b.harting.com/09300105457">https://b2b.harting.com/09300105457</a>

### Identification

Category	Hoods/Housings
Series of hoods/housings	Han <sup>®</sup> B
Type of hood/housing	Protection cover
Description of hood/housing	for hoods
	Metal
	With fixing cord
Type	Low construction
	High construction

### Version

Locking type	Double locking lever (on the hood)
Size	10 B
Field of application	Standard hoods/housings for industrial connectors

### Technical characteristics

Limiting temperature	-40 ... +125 °C
Degree of protection acc. to IEC 60529	IP65
Type rating acc. to UL 50 / UL 50E	4
	4X
	12

### Material properties

Material (seal)	NBR
RoHS	compliant
ELV status	compliant



Pushing Performance

## Material properties

China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No

## Specifications and approvals

Approvals	DNV GL
-----------	--------

## Commercial data

Packaging size	1
Net weight	56 g
Country of origin	Germany
European customs tariff number	85389099
eCl@ss	27440208 Cap for industrial connectors