

## HAR SERCOS III Typ B 4xAWG22/7 PVC 50m

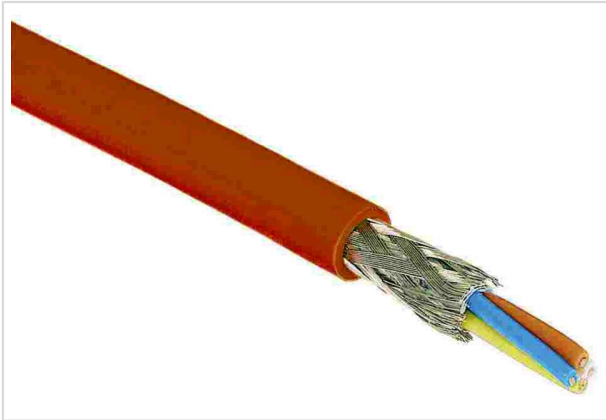


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 600 0144
Specification	HAR SERCOS III Typ B 4xAWG22/7 PVC 50m
HARTING eCatalogue	<a href="https://b2b.harting.com/09456000144">https://b2b.harting.com/09456000144</a>

### Identification

Category	System cabling
Element	Bulk cables
Specification	Not assembled
Type of cable	Copper cable (round)
Description of the cable	Flame retardant Sunlight resistant

### Version

Cable length	50 m
Number of cores	4
Core structure	4x AWG 22/7

### Technical characteristics

Transmission characteristics	Cat. 5 Class D up to 100 MHz
Data rate	10 Mbit/s 100 Mbit/s
Limiting temperature	-40 ... +70 °C -20 ... +60 °C During laying -50 ... +70 °C storage/transport
Minimum bending radius	5x Cable diameter (repeated bending) 3x Cable diameter (singular bending)
Torsional strength	≥ 10.000 @ torsion angle= ±180°/m
Conductor resistance @ 20 °C	≤120 Ω/km



**Pushing Performance**  
Since 1945

## Material properties

Material (cable)	PVC
Colour (cable)	Red
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained

## Specifications and approvals

Specifications	EN 13602
	UL 1685
	UL 1581
	UL style 21695

## Commercial data

Packaging size	1
Net weight	3 g
Net weight	68 g/m
Country of origin	Germany
European customs tariff number	85444290
GTIN	5713140273436
eCl@ss	27061801 Data and communication cable (copper)