

## Pneumatic module for 3 contacts

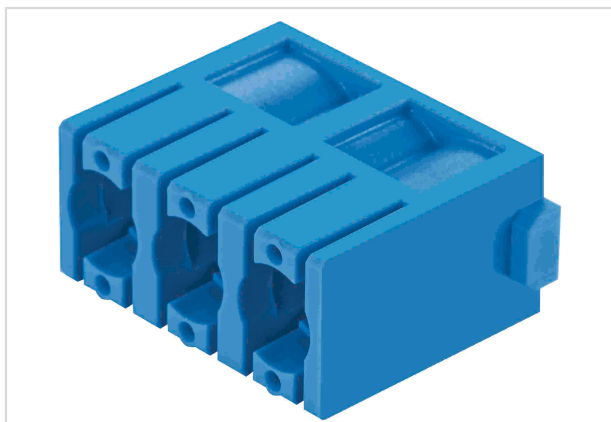


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 003 3501
Specification	Pneumatic module for 3 contacts
HARTING eCatalogue	<a href="https://b2b.harting.com/09140033501">https://b2b.harting.com/09140033501</a>

### Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® Pneumatic module

### Version

Gender	Male Female
Number of contacts	3
Details	Please order contacts separately.

### Technical characteristics

Limiting temperature	-40 ... +85 °C
Mating cycles	≥10,000

### Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	Blue
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No



Pushing Performance

## Material properties

REACH SVHC substances	No
-----------------------	----

## Specifications and approvals

Specifications	IEC 61984 EN 60664-1
UL / CSA	UL 1977 ECBT2.E235076 CSA-C22.2 No. 182.3 ECBT8.E235076

## Commercial data

Packaging size	2
Net weight	6.1 g
Country of origin	Germany
European customs tariff number	39269097
eCl@ss	27440220 Module for industrial connectors (pneumatic)