

## Han 16B Ex-HBM-Double Lever

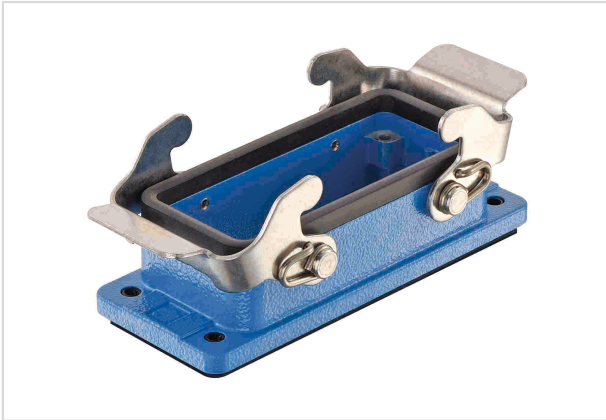


Image is for illustration purposes only. Please refer to product description.

Part number	09 36 016 1301
Specification	Han 16B Ex-HBM-Double Lever
HARTING eCatalogue	<a href="https://b2b.harting.com/09360161301">https://b2b.harting.com/09360161301</a>

### Identification

Category	Hoods/Housings
Series of hoods/housings	Han <sup>®</sup> Ex
Type of hood/housing	Bulkhead mounted housing

### Version

Locking type	Double locking lever
Size	16 B
Field of application	Connectors for explosion hazardous environments
Details	ATTENTION! Only to be used with Han <sup>®</sup> Ex inserts!

### Technical characteristics

Limiting temperature	-20 ... +40 °C
Degree of protection acc. to IEC 60529	IP65 With cable gland

### Material properties

Material (hood/housing)	Zinc die-cast
Surface (hood/housing)	Powder-coated
Colour (hood/housing)	RAL 5015 (sky blue)
Material (seal)	NBR
Material (locking)	Stainless steel
RoHS	compliant
ELV status	compliant
China RoHS	e



Pushing Performance

## Material properties

REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No

## Commercial data

Packaging size	1
Net weight	274 g
Country of origin	China
European customs tariff number	85389099
eCl@ss	27440202 Shell for industrial connectors