

## Han 10B-Base Panel 2 Levers IP 67

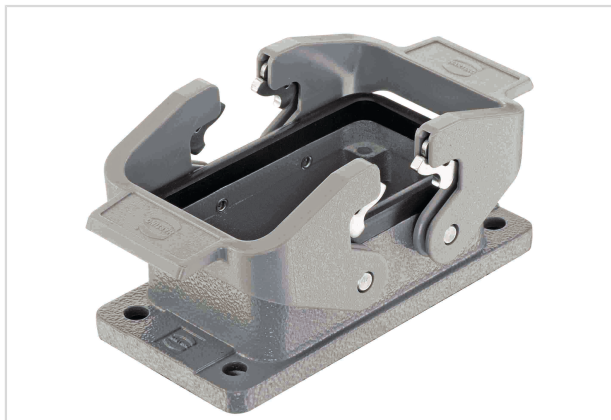


Image is for illustration purposes only. Please refer to product description.

|                    |   |
|--------------------|---|
| Part number        | 09 30 010 1301  |
| Specification      | Han 10B-Base Panel 2 Levers IP 67   |
| HARTING eCatalogue | <a href="https://b2b.harting.com/09300101301">https://b2b.harting.com/09300101301</a> |

### Identification

|                          |                          |
|--------------------------|--------------------------|
| Category                 | Hoods/Housings           |
| Series of hoods/housings | Han <sup>®</sup> B       |
| Type of hood/housing     | Bulkhead mounted housing |
| Type                     | Low construction         |

### Version

|                            |   |
|----------------------------|---|
| Locking type               | Double locking lever                              |
| Han-Easy Lock <sup>®</sup> | Yes   |
| Size                       | 10 B  |
| Field of application       | Standard hoods/housings for industrial connectors |

### Technical characteristics

|  |                 |
|--|-----------------|
| Limiting temperature                   | -40 ... +125 °C |
| Degree of protection acc. to IEC 60529 | IP65<br>IP67    |
| Type rating acc. to UL 50 / UL 50E     | 4<br>4X<br>12   |

### Material properties

|                         |                      |
|-------------------------|----------------------|
| Material (hood/housing) | Aluminium die-cast   |
| Surface (hood/housing)  | Powder-coated        |
| Colour (hood/housing)   | RAL 7037 (dust grey) |
| Material (seal)         | NBR                  |



Pushing Performance

## Material properties

|  |   |
|--|---|
| Material (locking)   | Polycarbonate (PC)<br>Stainless steel                     |
| Colour (locking)   | RAL 7037 (dust grey)                                      |
| Material flammability class acc. to UL 94 (locking levers) | V-0   |
| RoHS   | compliant   |
| ELV status   | compliant   |
| China RoHS   | e   |
| REACH Annex XVII substances                                | No  |
| REACH ANNEX XIV substances                                 | No  |
| REACH SVHC substances                                      | Yes   |
| REACH SVHC substances                                      | Potassium 1,1,2,2,3,3,4,4,4-nonafluorobutane-1-sulphonate |

## Specifications and approvals

|           |  |
|-----------|--|
| Approvals | DNV GL   |
| UL / CSA  | UL 1977 ECBT2.E235076<br>CSA-C22.2 No. 182.3 ECBT8.E235076 |
| CE        | Yes  |

## Commercial data

|                                |  |
|--------------------------------|--|
| Packaging size                 | 1  |
| Net weight                     | 123.5 g                                  |
| Country of origin              | China                                    |
| European customs tariff number | 85389099                                 |
| eCl@ss                         | 27440202 Shell for industrial connectors |