

Han 10B Protect Cover Die Cast

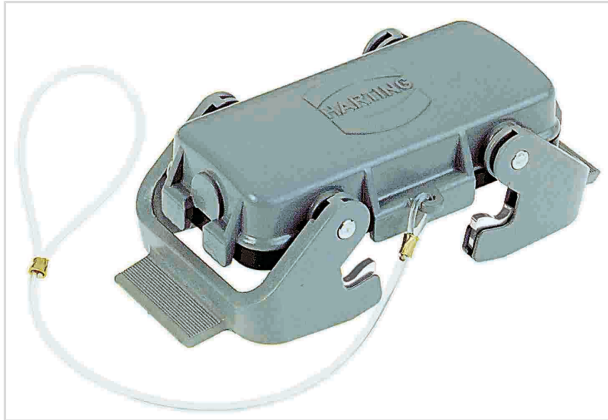


Image is for illustration purposes only. Please refer to product description.

Part number	09 30 010 5423
Specification	Han 10B Protect Cover Die Cast
HARTING eCatalogue	https://b2b.harting.com/09300105423

Identification

Category	Hoods/Housings
Series of hoods/housings	Han [®] B
Type of hood/housing	Protection cover
Description of hood/housing	for hoods
	Metal
	With fixing cord
Type	Low construction
	High construction

Version

Locking type	Double locking lever
Han-Easy Lock [®]	Yes
Size	10 B
Field of application	Standard hoods/housings for industrial connectors

Technical characteristics

Limiting temperature	-40 ... +125 °C
Degree of protection acc. to IEC 60529	IP65
Type rating acc. to UL 50 / UL 50E	4
	4X
	12

Material properties

Material (seal)	NBR
-----------------	-----



Pushing Performance

Material properties

Material (locking)	Polycarbonate (PC) Stainless steel
Colour (locking)	RAL 7037 (dust grey)
Material flammability class acc. to UL 94 (locking levers)	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	Yes
REACH SVHC substances	Potassium 1,1,2,2,3,3,4,4,4-nonafluorobutane-1-sulphonate

Specifications and approvals

Approvals	DNV GL
-----------	--------

Commercial data

Packaging size	1
Net weight	92.4 g
Country of origin	Germany
European customs tariff number	85389099
eCl@ss	27440208 Cap for industrial connectors