

## Han RJ45 module panel feed through, fem.

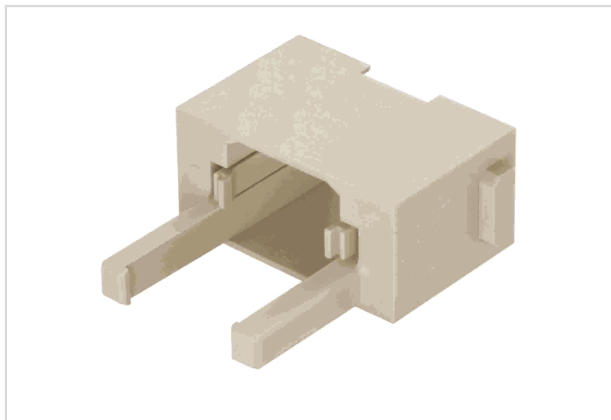


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 001 4722
Specification	Han RJ45 module panel feed through, fem.
HARTING eCatalogue	<a href="https://b2b.harting.com/09140014722">https://b2b.harting.com/09140014722</a>

### Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® RJ45 module
Description of the module	Single module

### Version

Gender	Female
Details	Please order insert separately.

### Technical characteristics

Rated current	1 A
Rated voltage	50 V
Rated impulse voltage	0.8 kV
Pollution degree	3
Rated voltage acc. to UL	30 V
Insulation resistance	$>10^{10} \Omega$
Limiting temperature	-40 ... +70 °C
Mating cycles	$\geq 500$

### Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0



Pushing Performance

## Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No

## Specifications and approvals

Specifications	EN 60664-1
	IEC 61984
Approvals	DNV GL

## Commercial data

Packaging size	1
Net weight	5 g
Country of origin	Germany
European customs tariff number	85389099
eCl@ss	27440218 Module for industrial connectors (data)