

Han 16M-Metal Cover-Bolt-for Base

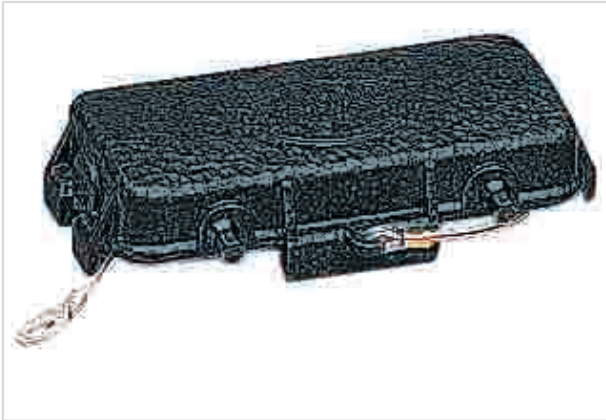


Image is for illustration purposes only. Please refer to product description.

Part number	09 37 016 5405
Specification	Han 16M-Metal Cover-Bolt-for Base
HARTING eCatalogue	https://b2b.harting.com/09370165405

Identification

Category	Hoods/Housings
Series of hoods/housings	Han [®] M
Type of hood/housing	Protection cover
Description of hood/housing	for bulkhead mounted housings
	for surface mounted housings
	for cable to cable housing
	Metal
Type	With fixing cord
	Low construction
	High construction

Version

Locking type	Double locking lever
Size	16 B
Field of application	Hoods/housings for rough environments

Technical characteristics

Limiting temperature	-40 ... +125 °C
Degree of protection acc. to IEC 60529	IP65
Type rating acc. to UL 50 / UL 50E	4
	4X
	12

Material properties

RoHS	compliant
------	-----------



Pushing Performance

Material properties

ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No

Specifications and approvals

Approvals	DNV GL
UL / CSA	UL 1977 ECBT2.E235076 CSA-C22.2 No. 182.3 ECBT8.E235076

Commercial data

Packaging size	1
Net weight	62.5 g
Country of origin	Germany
European customs tariff number	85389099
eCl@ss	27440208 Cap for industrial connectors