

## Han-Modular coax F-contact 75Ohm (RG179)

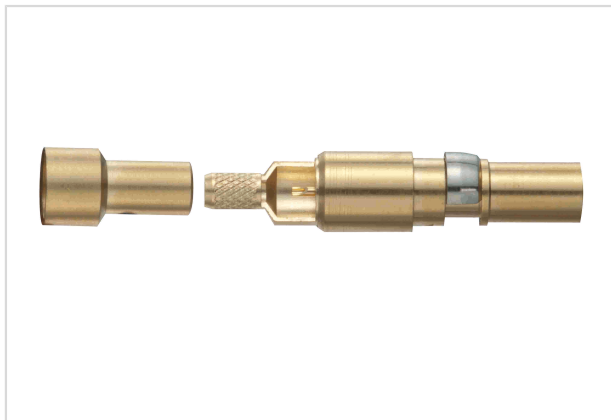


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 000 6221
Specification	Han-Modular coax F-contact 75Ohm (RG179)
HARTING eCatalogue	<a href="https://b2b.harting.com/09140006221">https://b2b.harting.com/09140006221</a>

### Identification

Category	Contacts
Series	DIN 41626
Type of contact	Coaxial contact
Description of the contact	for cables RG 179 BU, 187 AU

### Version

Termination method	Solder/crimp termination
Gender	Male
Manufacturing process	Turned contacts

### Technical characteristics

Operating current	$\leq 1.5$ A
Contact resistance	$\leq 10$ m $\Omega$
Impedance	75 $\Omega$

### Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Gold plated
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	No



Pushing Performance

## Material properties

REACH ANNEX XIV substances	No
REACH SVHC substances	Yes
REACH SVHC substances	Lead
ECHA SCIP number	b51e5b97-eeb5-438b-8538-f1771d43c17d

## Specifications and approvals

Specifications	EN 60664-1 IEC 61984
----------------	-------------------------

## Commercial data

Packaging size	10
Net weight	2.58 g
Country of origin	Hungary
European customs tariff number	85366910
eCl@ss	27440204 Contact for industrial connectors