


IPLD250-5C SHOWN

PART NUMBER	NO. OF PORTS	LENGTH
IPLD250-3C	3	2.98
IPLD250-4C	4	3.85
IPLD250-5C	5	4.71
IPLD250-6C	6	5.57
IPLD250-8C	8	7.29
IPLD250-10C	10	9.01
IPLD250-12C	12	10.74
IPLD250-14C	14	12.46

WIRE ENTRY POINT
WIRE RANGE: 250MCM - #6AWG
PRE-FILLED W/ OXIDE INHIBITOR

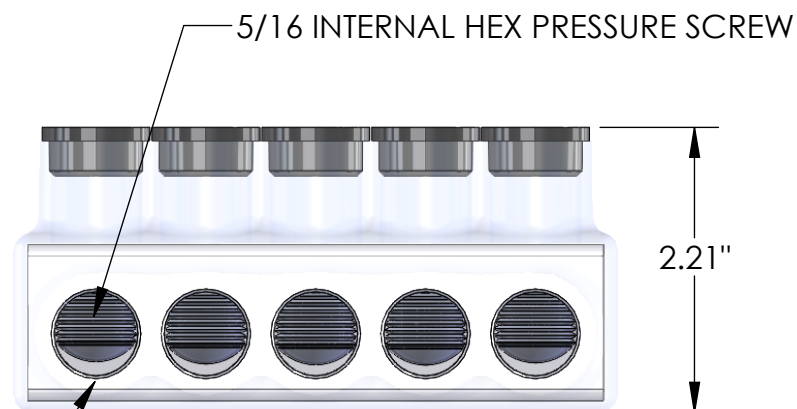

CONTACT NSi FOR SALES @ 800.321.5847



POLARIS
SALES . CO . INC

PROPRIETARY AND CONFIDENTIAL

11625 PROSPEROUS DRIVE ODESSA, FL 33556

THE INFORMATION CONTAINED IN THIS
DRAWING IS THE SOLE PROPERTY OF
POLARIS SALES CO. INC. ANY
REPRODUCTION IN PART OR AS A WHOLE
WITHOUT THE WRITTEN PERMISSION OF
POLARIS SALES CO. INC. IS PROHIBITED.

TITLE:

CLEAR INSULATED DUAL
ENTRY 250 CONNECTOR

NAME DATE
DRAWN BY T.MITCHELL 12/2021

DWG. NO.
IPLD250C SERIES

MATERIAL: N/A

SCALE: N/A

SHEET: 1 OF 1

NOTES:

1. CONNECTOR MANUFACTURED FROM 6061-T6 ALUMINUM ALLOY.
2. UL LISTED PER UL486A/B SPECIFICATIONS FOR 600V.
3. DUAL RATED FOR 90°C COPPER AND/OR ALUMINUM CONDUCTOR.
4. COLD TEMPERATURE RATED TO -45°C.
5. HIGH DIELECTRIC STRENGTH INSULATION IS ABRASION AND CHEMICAL RESISTANT.