



THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

PART NUMBER	GROMMET SIZE	CABLE DIAMETER	PART WEIGHT	PKG QTY
		in. (mm)	lbs. (g)	
CEG-02X1	SMALL	0.08 - 0.12 (2-3)	0.013 (5.75)	12
CEG-03X1	SMALL	0.12 - 0.16 (3-4)	0.012 (5.55)	12
CEG-04X1	SMALL	0.16 - 0.20 (4-5)	0.012 (5.37)	12
CEG-05X1	SMALL	0.20 - 0.24 (5-6)	0.011 (5.10)	12
CEG-06X1	SMALL	0.24 - 0.28 (6-7)	0.011 (4.85)	12
CEG-07X1	SMALL	0.28 - 0.31 (7-8)	0.01 (4.55)	12
CEG-08X1	SMALL	0.31 - 0.35 (8-9)	0.009 (4.00)	12
CEG-09X1	SMALL	0.35 - 0.39 (9-10)	0.008 (3.75)	12
CEG-10X1	SMALL	0.39 - 0.43 (10-11)	0.007 (3.35)	12
CEG-11X1	SMALL	0.43 - 0.47 (11-12)	0.006 (2.90)	12
CEG-12X1	MEDIUM	0.47 - 0.51 (12-13)	0.026 (12.00)	4
CEG-13X1	MEDIUM	0.51 - 0.55 (13-14)	0.024 (11.00)	4
CEG-14X1	MEDIUM	0.55 - 0.59 (14-15)	0.026 (12.00)	4
CEG-15X1	MEDIUM	0.59 - 0.63 (15-16)	0.022 (10.00)	4
CEG-16X1	MEDIUM	0.63 - 0.67 (16-17)	0.02 (9.00)	4
CEG-17X1	MEDIUM	0.67 - 0.71 (17-18)	0.018 (8.00)	4
CEG-18X1	MEDIUM	0.71 - 0.75 (18-19)	0.015 (7.00)	4
CEG-19X1	MEDIUM	0.75 - 0.79 (19-20)	0.015 (7.00)	4
CEG-20X1	MEDIUM	0.79 - 0.83 (20-21)	0.013 (6.00)	4
CEG-21X1	MEDIUM	0.83 - 0.87 (21-22)	0.011 (5.00)	4
CEG-22X1	LARGE	0.87 - 0.91 (22-23)	0.037 (17.00)	4
CEG-23X1	LARGE	0.91 - 0.94 (23-24)	0.035 (16.00)	4
CEG-24X1	LARGE	0.94 - 0.98 (24-25)	0.033 (15.00)	4
CEG-25X1	LARGE	0.98 - 1.02 (25-26)	0.031 (14.00)	4
CEG-26X1	LARGE	1.02 - 1.06 (26-27)	0.029 (13.00)	4
CEG-27X1	LARGE	1.06 - 1.10 (27-28)	0.026 (12.00)	4
CEG-28X1	LARGE	1.10 - 1.14 (28-29)	0.022 (10.00)	4
CEG-29X1	LARGE	1.14 - 1.18 (29-30)	0.02 (9.00)	4
CEGBLS	SMALL	BLANK	0.006 (2.50)	12
CEGBLM	MEDIUM	BLANK	0.011 (5.00)	4
CEGBLL	LARGE	BLANK	0.04 (18.00)	4
CEGAM*	MEDIUM	ADAPT FOR SMALL	0.021 (9.50)	4
CEGASIX2*	MEDIUM	FOR ASI LINE	0.03 (13.50)	4
CEG-02X2*	SMALL	0.08 - 0.12 (2-3)	0.013 (6.00)	12
CEG-02X4*	SMALL	0.08 - 0.12 (2-3)	0.011 (5.00)	12
CEG-03X2*	SMALL	0.12 - 0.16 (3-4)	0.012 (5.50)	12
CEG-03X4*	SMALL	0.12 - 0.16 (3-4)	0.011 (5.00)	12
CEG-04X2*	SMALL	0.16 - 0.20 (4-5)	0.011 (5.00)	12
CEG-04X4*	SMALL	0.16 - 0.20 (4-5)	0.009 (4.00)	12
CEG-05X2*	MEDIUM	0.20 - 0.24 (5-6)	0.013 (6.00)	4
CEG-05X4*	MEDIUM	0.20 - 0.24 (5-6)	0.026 (12.00)	4
CEG-06X2*	MEDIUM	0.24 - 0.28 (6-7)	0.029 (13.00)	4
CEG-06X4*	MEDIUM	0.24 - 0.28 (6-7)	0.024 (11.00)	4
CEG-07X2*	MEDIUM	0.28 - 0.31 (7-8)	0.026 (12.00)	4
CEG-07X4*	MEDIUM	0.28 - 0.31 (7-8)	0.022 (10.00)	4
CEG-08X2*	MEDIUM	0.31 - 0.35 (8-9)	0.026 (12.00)	4
CEG-08X4*	MEDIUM	0.31 - 0.35 (8-9)	0.02 (9.00)	4

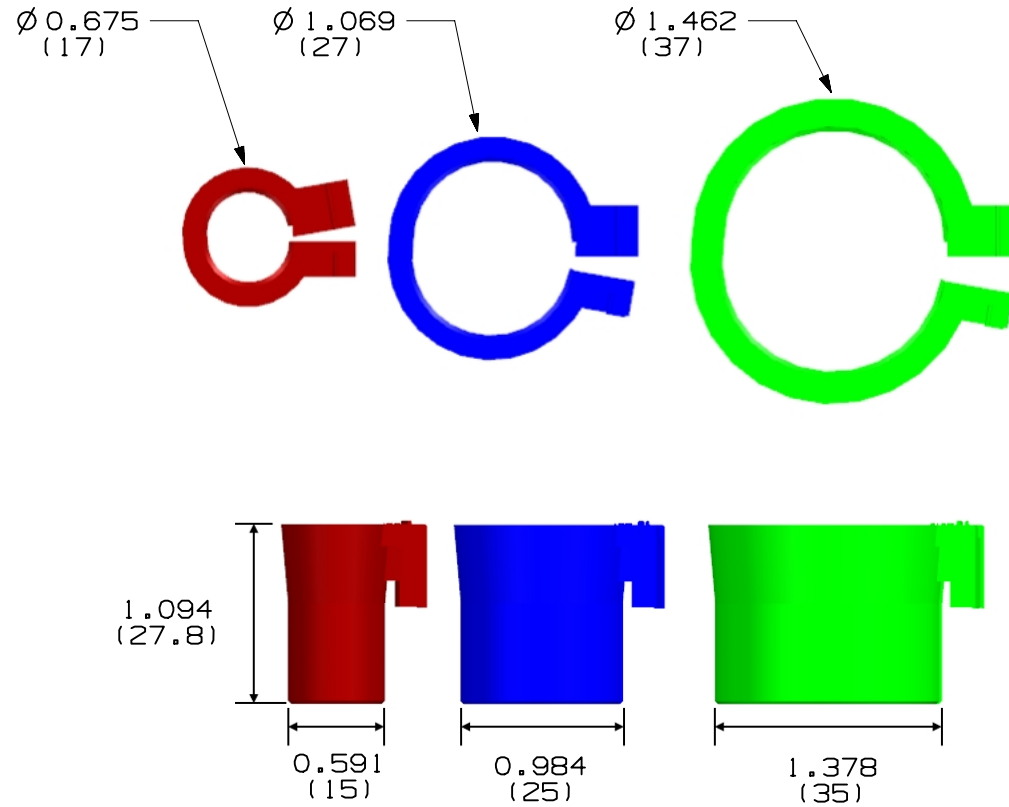

- NOTES:
- VISIT OUR ON-LINE CATALOG AT WWW.PANDUIT.COM FOR A LIST OF CURRENT PARTS APPLICABLE FOR USE WITH THIS PRODUCT.
  - DIMENSIONS IN [ ] ARE METRIC.
  - ALL MATERIALS AND COMPONENTS USED MEET THE MATERIAL RESTRICTIONS OF RoHS (EUROPEAN DIRECTIVE 2011/65/EU ON THE RESTRICTION OF HAZARDOUS SUBSTANCES) AS PROPOSED BY THE RoHS TECHNICAL ADAPTATION COMMITTEE.
  - MATERIAL: TPE
  - TEMPERATURE RANGE: -22 - 212 °F
  - FLAMMABILITY: VO
  - RoHS COMPLIANT
  - COMPLIANCE cURus, \*NONE
  - UV RESISTANT
  - WEIGHT: SEE TABLE

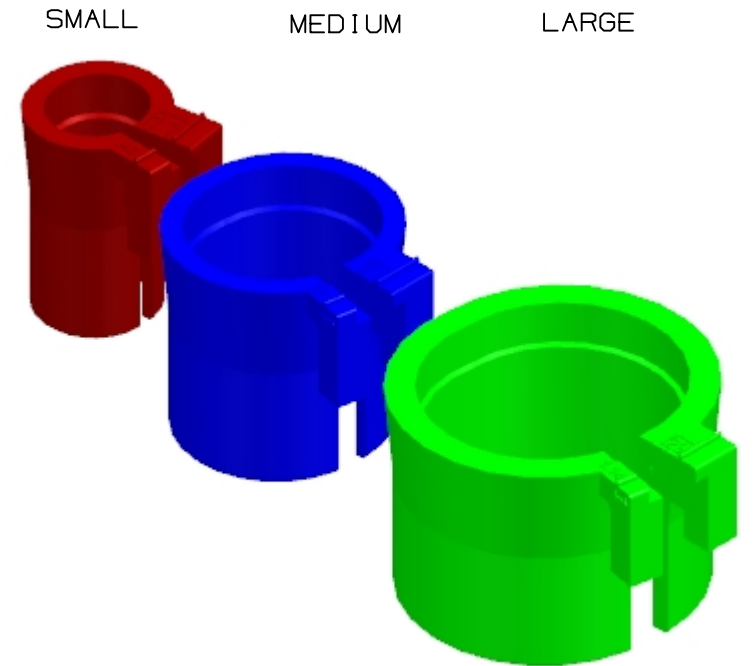

PART NUMBER		SEE TABLE	
TITLE		CEG Control Drawing	
		CUSTOMER DRAWING	
ITEM REVISION NAME	00872EBE/00	<b>PANDUIT</b>	
DATASET FILE NAME	00872EBE_DC/00A		
		THIRD ANGLE PROJECTION	
MATERIAL	SEE NOTE 4	DRAWING NUMBER	
		00872EBE - DC	
DRAWN BY	DATE	CHK	SCALE
SERH	9/13/2022	MDS	1:1
		SHEET 1 OF 1	
		B	

00A	9/13/2022	SERH	MDS	JADE	INITIAL RELEASE	124032/00
REV	DATE	BY	CHK	APR	DESCRIPTION	ECN

B

B

A

A

B-SIZE CUSTOMER